



Crimp die sets for insulated connectors according to DIN 46237



Art. No. 624 000 3 + 624 060 3 0

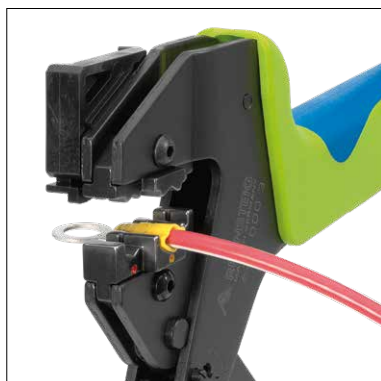

Art. No. 624 000 3 + 624 691 3 0 +
624 691 0 0125

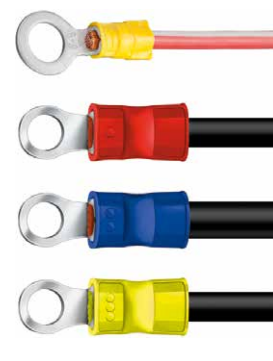

Art. No.	EAN 4049002	Capacity	Profile	Connectors	Illustration	Range of applications				
						PEW 12	E-PEW 12	CM 25-1	CM 25-5	CM 25-6
624 036 3 0	125003	0.1 – 0.5 mm ² non-insulated 0.1 – 0.5 mm ² insulated				•	•	•	•	•
624 060 3 0	014444	0.5 – 1.0 mm ² 1.5 – 2.5 mm ² 4.0 – 6.0 mm ²				•	•	•	•	•
624 060-6 3 0	111716	0.1 – 0.25 mm ² 0.3 – 0.5 mm ² 0.5 – 1.0 mm ²				•	•	•	•	•
624 063 3 0	016455	10.0 mm ² 16.0 mm ²				•	•	•	•	
624 691 3 0	025228	0.5 – 1.0 mm ² 4.0 – 6.0 mm ² 1.5 – 2.5 mm ²				•	•	•	•	•
624 691 0 0125	128134	Locator and Wire Stop				•	•	•*	•*	•*
624 1389 3 0	130700	1.5 – 2.5 mm ² 4.0 – 6.0 mm ² 0.5 – 1.0 mm ²				•	•	•	•	•

* without wire stop