




055011-055251

Double Head Socket Wrenches 6x6



PRODUCT DETAILS

- Double head socket wrenches in metric sizes
- From 16 mm onwards, with stud location hole
- 6 points Dynamic-Drive profile provides longer life for screws and nuts
- Finish: Chrome-plated matt finish
- Material: High performance alloy steel
- Hardness: 42-48 HRC
- Standards: UNE 16586

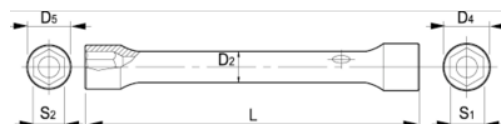

PRODUCT ATTRIBUTES

Product	S1	S2	D4	D5	D2	L	 g
055011	6 mm	7 mm	10 mm	11 mm	7 mm	103 mm	31 g
055031	8 mm	9 mm	12.5 mm	13.5 mm	9 mm	108 mm	53 g
055051	10 mm	11 mm	15 mm	16 mm	11 mm	120 mm	78 g
055071	12 mm	13 mm	17 mm	19 mm	13 mm	138 mm	127 g
055091	14 mm	15 mm	20 mm	21 mm	14 mm	143 mm	152 g
055121	16 mm	17 mm	22 mm	24 mm	16 mm	153 mm	185 g
055141	18 mm	19 mm	25 mm	26 mm	18 mm	163 mm	235 g
055171	20 mm	22 mm	28 mm	30 mm	20 mm	173 mm	312 g
055181	21 mm	23 mm	29 mm	31 mm	21 mm	183 mm	359 g
055201	24 mm	26 mm	33 mm	35 mm	24 mm	193 mm	438 g
055211	24 mm	27 mm	33 mm	37 mm	24 mm	193 mm	466 g
055221	25 mm	28 mm	34 mm	37 mm	25 mm	203 mm	535 g
055241	27 mm	29 mm	37 mm	39 mm	27 mm	208 mm	592 g
055251	30 mm	32 mm	40 mm	43 mm	30 mm	208 mm	737 g