




055301-055311

Stepped Handle for Double Head Socket Wrenches



PRODUCT DETAILS

- Tubular handle
- Handle to be used together with 055 wrench
- Finish: Chrome-plated matt finish
- Material: High performance alloy steel
- Hardness: 42-48 HRC
- Standards: DIN 900
- 055301: from 6x7 to 14x15
- 055311: from 16x17 to 30x32

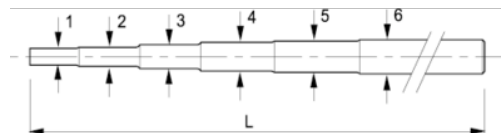

PRODUCT ATTRIBUTES

Product	1	2	3	4	5	6		L	
055301	3,1 mm	4,3 mm	5,3 mm	5,8 mm	8 mm	- mm	6x7 - 14x15	175 mm	54 g
055311	6,8 mm	7,8 mm	9,8 mm	11,8 mm	12,8 mm	14 mm	16x17 - 30x32	270 mm	251 g