




15-0607-1/15-3641-2
Double offset ring Wrenches



PRODUCT DETAILS

- Double end deep offset ring wrenches in metric sizes
- Finish: Chrome-plated matt finish
- Material: High performance alloy steel
- Hardness: 42-48 HRC
- Standards: ISO 10104, DIN 838
- - 1 retail packaging and -2 industrial packaging

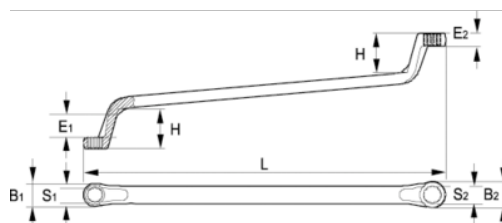

PRODUCT ATTRIBUTES

Product	S1	S2	B1	B2	E1	E2	Height of offset ring	L	 g
15-0607-1	6 mm	7 mm	10.8 mm	12.5 mm	4.9 mm	5.6 mm	20 mm	170 mm	45 g
15-0809-1	8 mm	9 mm	13.4 mm	15.3 mm	6 mm	6.8 mm	21 mm	182 mm	70 g
15-1011-1	10 mm	11 mm	16 mm	17.8 mm	7.4 mm	7.9 mm	23 mm	197 mm	90 g
15-1213-1	12 mm	13 mm	18.8 mm	20.2 mm	8.4 mm	8.9 mm	25 mm	213 mm	126 g
15-1415-1	14 mm	15 mm	20.8 mm	22.5 mm	9.4 mm	9.9 mm	26 mm	228 mm	155 g
15-1617-1	16 mm	17 mm	24.2 mm	25.7 mm	10.4 mm	10.9 mm	29 mm	246 mm	193 g
15-1719-1	17 mm	19 mm	27.6 mm	28.7 mm	11.4 mm	11.9 mm	31 mm	265 mm	243 g
15-1819-1	18 mm	19 mm	27.6 mm	28.7 mm	11.4 mm	11.9 mm	31 mm	265 mm	241 g
15-2022-1	20 mm	22 mm	29.7 mm	32.5 mm	12.4 mm	12.9 mm	33 mm	288 mm	315 g
15-2123-1	21 mm	23 mm	31 mm	33.2 mm	12.3 mm	13.3 mm	33 mm	310 mm	341 g
15-2426-1	24 mm	26 mm	34.8 mm	39.2 mm	13.7 mm	14.3 mm	34 mm	330 mm	478 g
15-2427-1	24 mm	27 mm	34.8 mm	39.2 mm	13.7 mm	14.3 mm	34 mm	330 mm	475 g
15-2528-1	25 mm	28 mm	36.6 mm	40.5 mm	14.2 mm	14.7 mm	35 mm	348 mm	548 g
15-2729-1	27 mm	29 mm	42 mm	45.2 mm	15 mm	16 mm	37 mm	372 mm	662 g
15-3032-1	30 mm	32 mm	42.2 mm	45.5 mm	14.8 mm	15.8 mm	37 mm	372 mm	635 g
15-3236-2	32 mm	36 mm	48.5 mm	54 mm	16.5 mm	17.8 mm	41 mm	417 mm	962 g
15-3641-2	36 mm	41 mm	53.5 mm	62 mm	17.3 mm	19.2 mm	48 mm	450 mm	1037 g