




18-06-1/18-32-1

Ratcheting Combination Wrenches



PRODUCT DETAILS

- Ratcheting combination wrenches in metric sizes
- Switch lever for quick change of right and left direction
- 15° angle for better handling and access
- Finish: Chrome-plated matt finish
- Material: High performance alloy steel
- Hardness: 40-50 HRC
- Standards: ISO 1711-1 and DIN 3113
- - 1 retail packaging

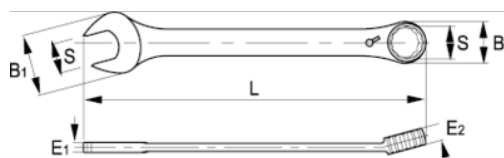

PRODUCT ATTRIBUTES

Product	S	B1	B2	E1	E2	L	
18-06-1	6 mm	15 mm	14.3 mm	4 mm	6.3 mm	128 mm	27 g
18-07-1	7 mm	16.4 mm	16.8 mm	4.4 mm	6.5 mm	138 mm	35 g
18-08-1	8 mm	18 mm	18.3 mm	4.8 mm	7.2 mm	140 mm	38 g
18-09-1	9 mm	20 mm	20 mm	4.8 mm	7.5 mm	150 mm	48 g
18-10-1	10 mm	22 mm	21.5 mm	5.1 mm	7.8 mm	160 mm	57 g
18-11-1	11 mm	24.5 mm	23.5 mm	5.5 mm	8.4 mm	165 mm	67 g
18-12-1	12 mm	26 mm	25 mm	5.9 mm	8.8 mm	170 mm	82 g
18-13-1	13 mm	28 mm	26.4 mm	6.4 mm	9.1 mm	180 mm	95 g
18-14-1	14 mm	30.8 mm	28 mm	6.7 mm	9.4 mm	190 mm	113 g
18-15-1	15 mm	33 mm	30 mm	7.3 mm	9.8 mm	200 mm	130 g
18-16-1	16 mm	24.5 mm	31 mm	7.8 mm	10.2 mm	210 mm	158 g
18-17-1	17 mm	37 mm	33 mm	8 mm	10.5 mm	225 mm	180 g
18-18-1	18 mm	39.5 mm	35 mm	8.2 mm	10.8 mm	235 mm	213 g
18-19-1	19 mm	40.8 mm	36 mm	8.4 mm	11.2 mm	245 mm	233 g
18-21-1	21 mm	44.8 mm	42 mm	9 mm	13.5 mm	290 mm	343 g
18-22-1	22 mm	44.8 mm	42 mm	9 mm	13.5 mm	290 mm	345 g
18-24-1	24 mm	52.8 mm	48 mm	9.7 mm	14.5 mm	332 mm	503 g
18-27-1	27 mm	56 mm	53 mm	10.8 mm	15.7 mm	359 mm	550 g
18-30-1	30 mm	62 mm	58 mm	11.2 mm	17 mm	404 mm	750 g
18-32-1	32 mm	65 mm	62 mm	12 mm	17.5 mm	424 mm	900 g