




25-06-1/25-100-2
Combination Wrenches, mm



PRODUCT DETAILS

- Combination wrench in metric sizes
- Finish: Chrome-plated matt finish
- Material: High performance alloy steel
- Hardness: 42-50 HRC
- Standards: ISO 10102
- - 1 retail packaging, -2 industrial packaging

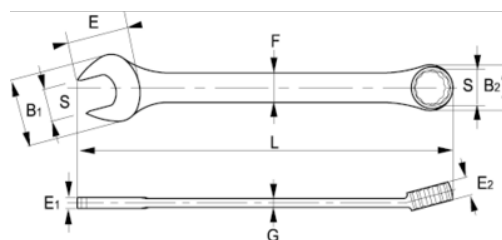

PRODUCT ATTRIBUTES

Product	S	L	B1	B2	F	E	E1	E2	G	
25-06-2	6 mm	103 mm	15.7 mm	10.6 mm	6.2 mm	7.9 mm	3.7 mm	5.2 mm	3 mm	15 g
25-06-1	6 mm	103 mm	15.7 mm	10.6 mm	6.2 mm	7.9 mm	3.7 mm	5.2 mm	3 mm	15 g
25-07-2	7 mm	109 mm	18 mm	12.1 mm	6.8 mm	8.2 mm	3.7 mm	5.5 mm	3 mm	17 g
25-07-1	7 mm	109 mm	18 mm	12.1 mm	6.8 mm	8.2 mm	3.7 mm	5.5 mm	3 mm	17 g
25-08-1	8 mm	119 mm	18.8 mm	13.6 mm	6.8 mm	9.9 mm	4 mm	6 mm	3.3 mm	21 g
25-08-2	8 mm	119 mm	18.8 mm	13.6 mm	6.8 mm	9.9 mm	4 mm	6 mm	3.3 mm	21 g
25-09-1	9 mm	124 mm	21 mm	15.1 mm	7.9 mm	10.4 mm	4 mm	6.8 mm	3.4 mm	26 g
25-09-2	9 mm	124 mm	21 mm	15.1 mm	7.9 mm	10.4 mm	4 mm	6.8 mm	3.4 mm	26 g
25-10-1	10 mm	134 mm	22.8 mm	16.2 mm	8.6 mm	10.7 mm	4.8 mm	7 mm	3.6 mm	38 g
25-10-2	10 mm	134 mm	22.8 mm	16.2 mm	8.6 mm	10.7 mm	4.8 mm	7 mm	3.6 mm	38 g
25-11-1	11 mm	143 mm	25.8 mm	17.1 mm	9.1 mm	12.6 mm	4.8 mm	7.5 mm	3.6 mm	39 g
25-11-2	11 mm	143 mm	25.8 mm	17.1 mm	9.1 mm	12.6 mm	4.8 mm	7.5 mm	3.6 mm	39 g
25-12-1	12 mm	154 mm	27.8 mm	18.9 mm	10 mm	13.2 mm	5.2 mm	8 mm	4.2 mm	51 g
25-12-2	12 mm	154 mm	27.8 mm	18.9 mm	10 mm	13.2 mm	5.2 mm	8 mm	4.2 mm	51 g
25-13-1	13 mm	164 mm	29.8 mm	20.2 mm	11.5 mm	14.6 mm	5.2 mm	8.3 mm	4.2 mm	63 g
25-13-2	13 mm	164 mm	29.8 mm	20.2 mm	11.5 mm	14.6 mm	5.2 mm	8.3 mm	4.2 mm	63 g
25-14-1	14 mm	174 mm	29.8 mm	21.2 mm	11.4 mm	15.8 mm	5.8 mm	8.9 mm	4.6 mm	68 g
25-14-2	14 mm	174 mm	29.8 mm	21.2 mm	11.4 mm	15.8 mm	5.8 mm	8.9 mm	4.6 mm	68 g
25-15-1	15 mm	183 mm	34.1 mm	22.3 mm	12.2 mm	16.9 mm	5.8 mm	8.9 mm	4.6 mm	85 g
25-15-2	15 mm	183 mm	34.1 mm	22.3 mm	12.2 mm	16.9 mm	5.8 mm	8.9 mm	4.6 mm	85 g
25-16-1	16 mm	194 mm	35.1 mm	23.8 mm	13.2 mm	17.6 mm	6.3 mm	9.5 mm	5 mm	107 g
25-16-2	16 mm	194 mm	35.1 mm	23.8 mm	13.2 mm	17.6 mm	6.3 mm	9.5 mm	5 mm	107 g
25-17-1	17 mm	203 mm	37.2 mm	25.3 mm	14.4 mm	18.6 mm	6.3 mm	10 mm	5 mm	118 g
25-17-2	17 mm	203 mm	37.2 mm	25.3 mm	14.4 mm	18.6 mm	6.3 mm	10 mm	5 mm	118 g
25-18-1	18 mm	214 mm	39.2 mm	26.8 mm	14.4 mm	20.5 mm	6.7 mm	10.5 mm	5.2 mm	137 g
25-18-2	18 mm	214 mm	39.2 mm	26.8 mm	14.4 mm	20.5 mm	6.7 mm	10.5 mm	5.2 mm	137 g
25-19-1	19 mm	228 mm	41.4 mm	28.3 mm	15.8 mm	21.1 mm	7 mm	11.2 mm	5.2 mm	163 g
25-19-2	19 mm	228 mm	41.4 mm	28.3 mm	15.8 mm	21.1 mm	7 mm	11.2 mm	5.2 mm	163 g
25-20-1	20 mm	240 mm	42.4 mm	29.7 mm	17.3 mm	22.8 mm	7.5 mm	11.4 mm	5.5 mm	186 g
25-20-2	20 mm	240 mm	42.4 mm	29.7 mm	17.3 mm	22.8 mm	7.5 mm	11.4 mm	5.5 mm	186 g
25-21-1	21 mm	249.5 mm	45.4 mm	32.4 mm	17.3 mm	22.8 mm	8.6 mm	12.6 mm	6 mm	210 g
25-21-2	21 mm	249.5 mm	45.4 mm	32.4 mm	17.3 mm	22.8 mm	8.6 mm	12.6 mm	6 mm	210 g
25-22-1	22 mm	249.5 mm	45.4 mm	32.4 mm	17.3 mm	22.8 mm	8.6 mm	12.2 mm	6 mm	202 g
25-22-2	22 mm	249.5 mm	45.4 mm	32.4 mm	17.3 mm	22.8 mm	8.6 mm	12.2 mm	6 mm	202 g
25-23-1	23 mm	270 mm	49.7 mm	36.1 mm	20.3 mm	25 mm	9.2 mm	13.6 mm	6.4 mm	281 g
25-23-2	23 mm	270 mm	49.7 mm	36.1 mm	20.3 mm	25 mm	9.2 mm	13.6 mm	6.4 mm	281 g
25-24-1	24 mm	270 mm	49.7 mm	36.1 mm	20.3 mm	25 mm	9.2 mm	13.6 mm	6.4 mm	276 g
25-24-2	24 mm	270 mm	49.7 mm	36.1 mm	20.3 mm	25 mm	9.2 mm	13.6 mm	6.4 mm	276 g
25-25-1	25 mm	289.5 mm	53.4 mm	39.6 mm	22.5 mm	27.6 mm	9.6 mm	14.2 mm	6.8 mm	346 g
25-25-2	25 mm	289.5 mm	53.4 mm	39.6 mm	22.5 mm	27.6 mm	9.6 mm	14.2 mm	6.8 mm	346 g
25-26-1	26 mm	289.5 mm	53.4 mm	39.6 mm	22.5 mm	27.6 mm	9.6 mm	14.2 mm	6.8 mm	345 g
25-26-2	26 mm	289.5 mm	53.4 mm	39.6 mm	22.5 mm	27.6 mm	9.6 mm	14.2 mm	6.8 mm	345 g
25-27-1	27 mm	310 mm	58.4 mm	41.6 mm	23.3 mm	29.5 mm	10 mm	14.6 mm	7.2 mm	382 g
25-27-2	27 mm	310 mm	58.4 mm	41.6 mm	23.3 mm	29.5 mm	10 mm	14.6 mm	7.2 mm	382 g
25-28-1	28 mm	310 mm	58.4 mm	41.6 mm	23.3 mm	29.5 mm	10 mm	14.6 mm	7.2 mm	402 g
25-28-2	28 mm	310 mm	58.4 mm	41.6 mm	23.3 mm	29.5 mm	10 mm	14.6 mm	7.2 mm	402 g
25-29-1	29 mm	330 mm	60.4 mm	45.6 mm	23.3 mm	32.1 mm	10.6 mm	15.6 mm	7.6 mm	476 g
25-29-2	29 mm	330 mm	60.4 mm	45.6 mm	23.3 mm	32.1 mm	10.6 mm	15.6 mm	7.6 mm	476 g
25-30-1	30 mm	330 mm	60.4 mm	45.6 mm	23.3 mm	32.1 mm	10.6 mm	15.6 mm	7.6 mm	468 g
25-30-2	30 mm	330 mm	60.4 mm	45.6 mm	23.3 mm	32.1 mm	10.6 mm	15.6 mm	7.6 mm	468 g
25-32-2	32 mm	349 mm	67.4 mm	48.8 mm	25.3 mm	35.6 mm	11.2 mm	17.8 mm	8 mm	567 g
25-32-1	32 mm	349 mm	67.4 mm	48.8 mm	25.3 mm	35.6 mm	11.2 mm	17.8 mm	8 mm	567 g
25-34-1	34 mm	350 mm	67.4 mm	48.8 mm	25.3 mm	35.6 mm	11.2 mm	17.8 mm	8 mm	541 g
25-34-2	34 mm	350 mm	67.4 mm	48.8 mm	25.3 mm	35.6 mm	11.2 mm	17.8 mm	8 mm	541 g
25-36-2	36 mm	401 mm	74 mm	54 mm	31 mm	62 mm	10.4 mm	17 mm	8 mm	787 g
25-41-2	41 mm	436 mm	82 mm	61 mm	34 mm	70 mm	12 mm	19.5 mm	8 mm	1070 g
25-46-2	46 mm	556 mm	92 mm	66 mm	33.6 mm	79.8 mm	15 mm	23 mm	11 mm	1750 g
25-50-2	50 mm	602 mm	100 mm	73 mm	36.6 mm	86.7 mm	17 mm	26 mm	12 mm	2200 g
25-55-2	55 mm	612 mm	113 mm	84 mm	42 mm	94 mm	18 mm	28 mm	14.5 mm	3070 g
25-60-2	60 mm	660 mm	125 mm	90 mm	47 mm	100 mm	20 mm	30 mm	16 mm	3500 g
25-65-2	65 mm	710 mm	132 mm	98 mm	52 mm	110 mm	21 mm	34 mm	18 mm	4750 g
25-70-2	70 mm	760 mm	140 mm	102 mm	52 mm	110 mm	22 mm	35 mm	18 mm	5550 g
25-75-2	75 mm	810 mm	150 mm	108 mm	55 mm	120 mm	25 mm	38 mm	19 mm	6800 g
25-80-2	80 mm	820 mm	179 mm	131 mm	60 mm	120 mm	30 mm	38 mm	20 mm	10000 g
25-85-2	85 mm	820 mm	179 mm	131 mm	60 mm	120 mm	30 mm	38 mm	20 mm	10000 g
25-90-2	90 mm	790 mm	179 mm	131 mm	60 mm	120 mm	30 mm	38 mm	20 mm	10000 g
25-95-2	95 mm	860 mm	187 mm	145 mm	62 mm	120 mm	32 mm	43 mm	20 mm	12000 g
25-100-2	100 mm	860 mm	187 mm	145 mm	62 mm	120 mm	32 mm	43 mm	20 mm	12000 g