




**413V-0-100/413V-3-200**

**Insulated Screwdrivers Pozidriv**

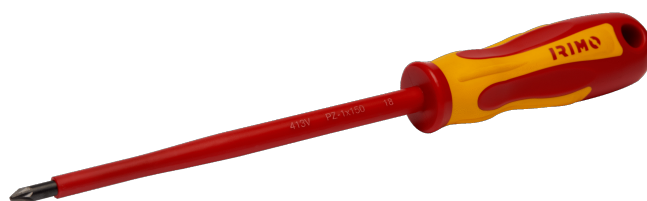

## PRODUCT DETAILS

- Insulated VDE screwdriver for Pozidriv head screws
- Phosphate finish tip for higher accuracy
- For working on live equipment up to 1000 V
- Two-component handle for comfortable grip and high torque transfer
- Non-rolling handle shape
- Integrated hanging hole
- High quality blade insulation moulded directly onto the blade for total safety
- Permanently marked blade with size and part number for easy identification
- Individually inspected and manufactured according to IEC 60900, tested in a water bath at 10,000 V
- Standards: ISO 8764/DIN 5260



## PRODUCT ATTRIBUTES

| Product           |  |  |  |  |  |  |
|-------------------|-------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------|
| <b>413V-0-100</b> | PZ 0                                                                                | 100 mm                                                                              | 26 mm                                                                               | 90 mm                                                                                 | 190 mm                                                                                | 40 g                                                                                  |
| <b>413V-1-150</b> | PZ 1                                                                                | 150 mm                                                                              | 30 mm                                                                               | 110 mm                                                                                | 260 mm                                                                                | 80 g                                                                                  |
| <b>413V-2-175</b> | PZ 2                                                                                | 175 mm                                                                              | 30 mm                                                                               | 110 mm                                                                                | 285 mm                                                                                | 120 g                                                                                 |
| <b>413V-3-200</b> | PZ 3                                                                                | 200 mm                                                                              | 37 mm                                                                               | 120 mm                                                                                | 320 mm                                                                                | 180 g                                                                                 |