




T49T20-T49T60 10 mm Bits Torx® 115 mm

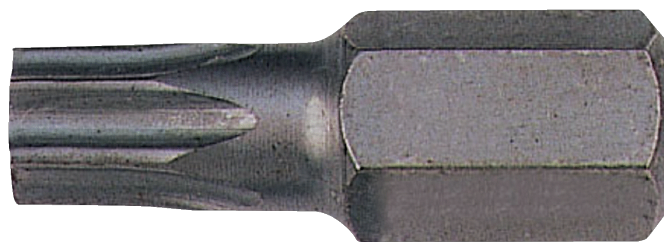

PRODUCT DETAILS

- For Torx® head screws
- 10 mm hex drive DIN 3126 and ISO 1173 Style C 10
- For the automotive sector
- High performance alloy steel
- Matte chrome plated finish for sockets
- Zinc phosphate finish for bits
- Single pack



PRODUCT ATTRIBUTES

Product					
T49T20	1	T20	3.84 mm	30 mm	6.5 g
T49T25	1	T25	4.4 mm	30 mm	6.5 g
T49T27	1	T27	4.96 mm	30 mm	6.5 g
T49T30	1	T30	5.49 mm	30 mm	6.5 g
T49T40	1	T40	6.6 mm	30 mm	6.5 g
T49T45	1	T45	7.7 mm	30 mm	6.5 g
T49T50		T50	8.79 mm	30 mm	6.5 g
T49T55		T55	11.17 mm	30 mm	6.5 g
T49T60	1	T60	13.2 mm	30 mm	6.5 g