


Technical data sheet

Cone cable gland, PG thread, light grey

Item no. 2036428

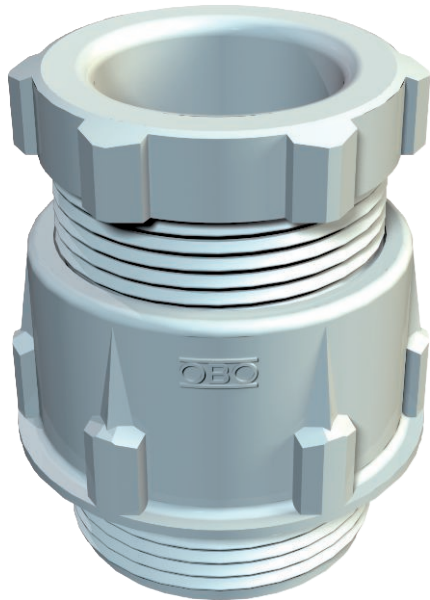

Standard cable gland, shape A, to DIN 46320 with simple NR/SBR sealing ring.

PG connection thread in accordance with DIN 40430.

Protection rating: with connection thread sealing ring IP65, without connection thread sealing ring IP54.

Note: Only tighten polystyrene cable glands lightly due to the risk of stress crack formation.



PS Polystyrene

Additional product text 1 Shock-resistant

Master data

Item no.	2036428
Type	106 PG42
Description 1	Cable gland
Dimension	PG42
Colour	Light grey
RAL number	7035
Material	Polystyrene
Material symbol	PS
Smallest sales unit (VG)	5,00 Piece
Weight	6,70 kg/100 pc.


Technical data sheet

Cone cable gland, PG thread, light grey

Item no. 2036428



Technical data

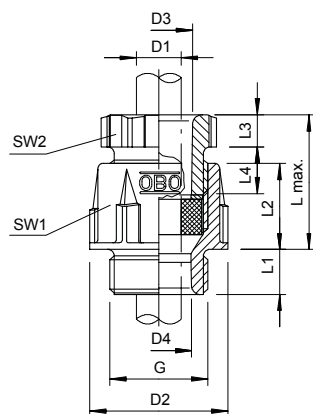

Dimension D2	65,00 mm
Dimension D3	44,50 mm
Dimension D4	40,50 mm
Dimension L max.	48,00 mm
Dimension L1	13,00 mm
Dimension L2	27,00 mm
Dimension L3	9,00 mm
Dimension L4	18,50 mm
SW 1	60,00 mm
SW 2	55,00 mm
Version	Straight
Type of seal	Sealing ring
Bend protection	☐
Sealing range D	30,00 - 38,00 mm
explosion-proof	☐
For Ex zone	Without
For Ex zone gas	Without
For Ex zone dust	Without
Thread	Pg 42
Thread type	PG
Thread length	13,00 mm
Nominal thread size	42,00
Fibre-glass reinforced	☐
Halogen-free	☒
Multiple sealing insert	☐
With locknut	☐
Impact-resistant	☐
Protection rating	IP65
Splittable gland	☐
Strain relief option	☐