


Technical data sheet

Cone cable gland, PG thread, light grey

Item no. 2036487

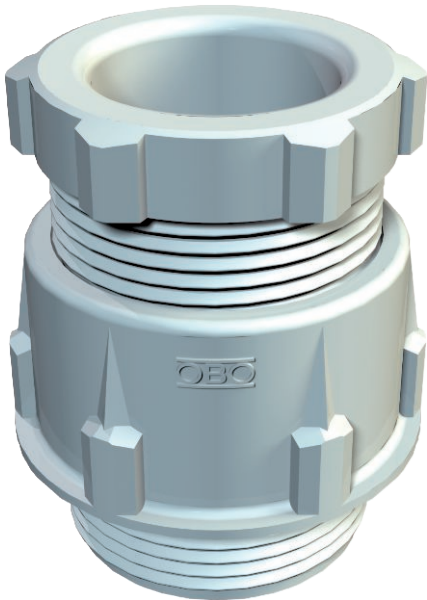

Standard cable gland, shape A, to DIN 46320 with simple NR/SBR sealing ring.
PG connection thread in accordance with DIN 40430.
Protection rating: with connection thread sealing ring IP65, without connection thread sealing ring IP54.
Note: Only tighten polystyrene cable glands lightly due to the risk of stress crack formation.

CE

IP 54

IP 65

Pg

PS

Polystyrene

Additional product text 1

Shock-resistant

Master data	
Item no.	2036487
Type	106 PG48
Description 1	Cable gland
Dimension	PG48
Colour	Light grey
RAL number	7035
Material	Polystyrene
Material symbol	PS
Smallest sales unit (VG)	5,00 Piece
Weight	7,34 kg/100 pc.


Technical data sheet

Cone cable gland, PG thread, light grey

Item no. 2036487



Technical data

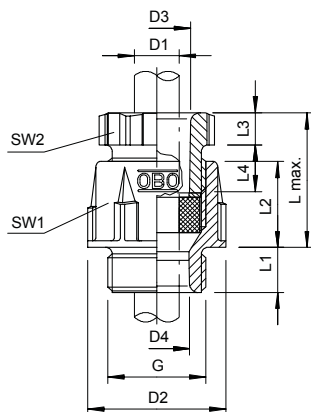

Dimension D2	70,00 mm
Dimension D3	50,00 mm
Dimension D4	45,50 mm
Dimension L max.	48,00 mm
Dimension L1	14,00 mm
Dimension L2	27,00 mm
Dimension L3	9,00 mm
Dimension L4	18,50 mm
SW 1	65,00 mm
SW 2	60,00 mm
Version	Straight
Type of seal	Sealing ring
Bend protection	☐
Sealing range D	37,00 - 44,00 mm
explosion-proof	☐
For Ex zone	Without
For Ex zone gas	Without
For Ex zone dust	Without
Thread	Pg 48
Thread type	PG
Thread length	14,00 mm
Nominal thread size	48,00
Fibre-glass reinforced	☐
Halogen-free	☒
Multiple sealing insert	☐
With locknut	☐
Impact-resistant	☐
Protection rating	IP65
Splittable gland	☐
Strain relief option	☐