

# Technical data sheet

## Locknut, metric thread

Item no. 2049589



Locknut to DIN 46319, with metric thread IEC 423.

Note: Only tighten polystyrene cable glands lightly due to the risk of stress crack formation.




**PS** Polystyrene

### Master data

|                          |                 |
|--------------------------|-----------------|
| Item no.                 | 2049589         |
| Type                     | 116 M63 LGR PS  |
| Description 1            | Locknut         |
| Dimension                | M63             |
| Colour                   | Light grey      |
| RAL number               | 7035            |
| Material                 | Polystyrene     |
| Material symbol          | PS              |
| Smallest sales unit (VG) | 25,00 Piece     |
| Weight                   | 1,03 kg/100 pc. |

### Technical data

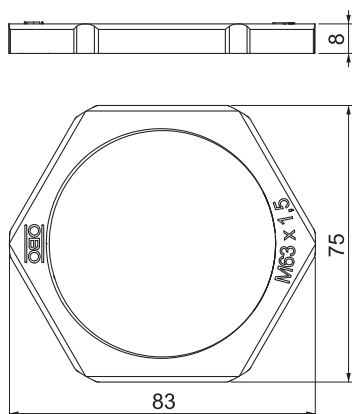

|                               |                                     |
|-------------------------------|-------------------------------------|
| Dimension E                   | 83,00 mm                            |
| Dimension L                   | 8,00 mm                             |
| WAF                           | 75,00 mm                            |
| Thread type                   | Metric                              |
| Thread                        | M63 x 1,5                           |
| Nominal thread size metric/PG | 63,00                               |
| Fibre-glass reinforced        | <input type="checkbox"/>            |
| Halogen-free                  | <input checked="" type="checkbox"/> |
| Impact-resistant              | <input checked="" type="checkbox"/> |