

Technical data sheet

Cap nut cable gland, metric thread, silver grey, long,
nickel-plated

Item no. 2086111



With metric connecting thread to IEC 423 robust cap-nut cable gland with large sealing area.
Strain relief, wringing protection and tightness over the whole clamping area. For thicker housing
wall thicknesses in conjunction with locknuts. Neoprene sealing ring. Polyamide terminal insert.
With pre-mounted sealing ring on connection thread, VDE-tested to DIN EN 50262, protection
rating IP 68 at 5 bar for 1 hr.

With long connection thread.

* Prices according to DEL notation.



CuZn	Brass
N	Nickel-plated

Master data

Item no.	2086111
Type	V-TEC VM LM12 MS
Description 1	Cable gland
Description 2	with long connection thread
Dimension	M12
Material	Brass
Material symbol	CuZn
Surface	Nickel-plated
Surface symbol	N
Smallest sales unit (VG)	50,00 Piece
Weight	1,30 kg/100 pc.


Technical data sheet

Cap nut cable gland, metric thread, silver grey, long,
nickel-plated

Item no. 2086111



Technical data

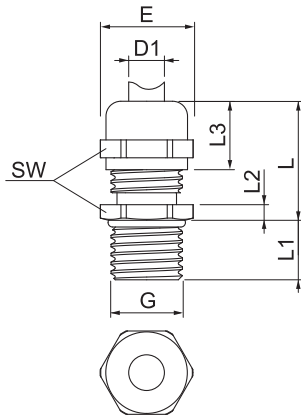

Dimension E	15,50 mm
Dimension L max.	20,00 mm
Dimension L1	10,00 mm
Dimension L2	3,00 mm
Dimension L3	11,50 mm
WAF	14,00 mm
Version	Straight
Type of seal	Sealing ring
Bend protection	☐
Sealing range D	3,00 - 6,00 mm
explosion-proof	☐
Flat cable threaded connection	☐
For Ex zone	Without
Thread	M12 x 1,5
Thread type	Metric
Thread length	10,00 mm
Fibre-glass reinforced	☐
Halogen-free	☐
Multiple sealing insert	☐
With locknut	☐
Impact-resistant	☐
Protection rating	IP68
max. permitted ambient temperature	-20,00 - 100,00 °C
Strain relief option	☒