

Technical data sheet

Cap nut cable gland, metric thread, silver grey, long,
nickel-plated
Item no. 2086147



With metric connecting thread to IEC 423 robust cap-nut cable gland with large sealing area.
Strain relief, wringing protection and tightness over the whole clamping area. For thicker housing
wall thicknesses in conjunction with locknuts. Neoprene sealing ring. Polyamide terminal insert.
With pre-mounted sealing ring on connection thread, VDE-tested to DIN EN 50262, protection
rating IP 68 at 5 bar for 1 hr.
With long connection thread.
* Prices according to DEL notation.



CuZn	Brass
N	Nickel-plated

Master data

Item no.	2086147
Type	V-TEC VM LM50 MS
Description 1	Cable gland
Description 2	with long connection thread
Dimension	M50
Material	Brass
Material symbol	CuZn
Surface	Nickel-plated
Surface symbol	N
Smallest sales unit (VG)	5,00 Piece
Weight	24,00 kg/100 pc.


Technical data sheet

Cap nut cable gland, metric thread, silver grey, long,
nickel-plated

Item no. 2086147



Technical data

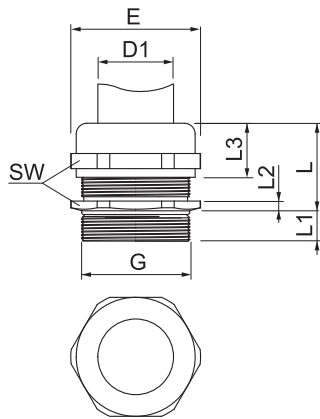

Dimension E	60,00 mm
Dimension L max.	38,50 mm
Dimension L1	14,00 mm
Dimension L2	4,50 mm
Dimension L3	25,00 mm
WAF	55,00 mm
Version	Straight
Type of seal	Sealing ring
Bend protection	☐
Sealing range D	24,00 - 35,00 mm
explosion-proof	☐
Flat cable threaded connection	☐
For Ex zone	Without
Thread	M50 x 1,5
Thread type	Metric
Thread length	14,00 mm
Fibre-glass reinforced	☐
Halogen-free	☐
Multiple sealing insert	☐
With locknut	☐
Impact-resistant	☐
Protection rating	IP68
max. permitted ambient temperature	-20,00 - 100,00 °C
Strain relief option	☒