





DC Power Cable 3m long
Socket 2.5x5.5 mm
 flexible, multiwire conductors,
 stranded of bare copper wires
2x0.50mm² - double insulation

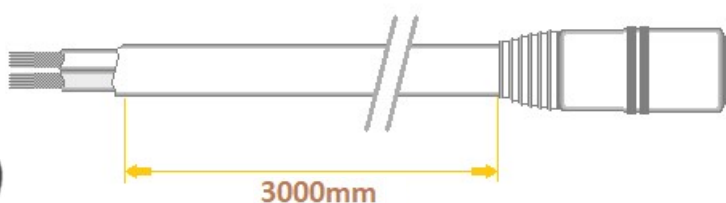

Model	S25-TT-O050-300BK
DC Plug (output)	tinned terminals
DC Socket (input)	2.5x5.5mm , (round plug, outer diameter 5.5mm, inner diameter 2.5mm)
Construction	flexible, multiwire conductors, stranded of bare annealed copper wires
Cable cross section	3.6mm
Wire diameter	2x0.5mm²
Nominal voltage	0-100V
Rated current	1.5A
Length	300cm
Jacket	PVC
Color	Black
Inner conductor	Cu
Insulation resistance	>100MΩ @ 500VDC
Insulation thickness	0.6mm (2x0.3mm)
Allowable operation temperature	-20°C to 70°C
Maximum wire resistance	39 Ω/km @ 20°C

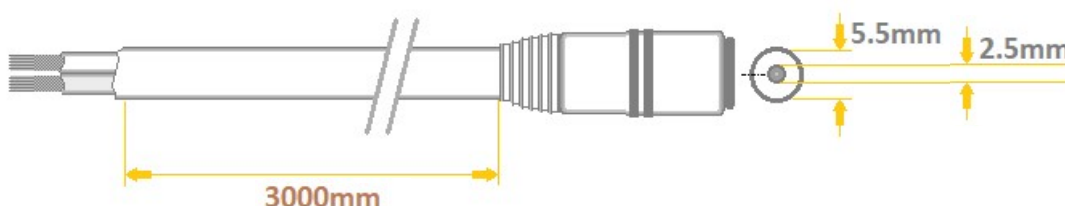

Marking System

model:

S25-TT-O050-300BK

1		2		3		4		5		6		7		8	
S	25	-	T	T	-	O	050	-	300	BK					

1	Input / Output (side 1)	P - straight plug A - angled plug S - socket
2	Plug / Socket dimensions (side 1)	07 - 0.7mm / 2.35mm 13 - 1.3mm / 3.5mm 40 - 1.7mm / 4.0mm 48 - 1.7mm / 4.8mm 55 - 1.7mm / 5.5mm 21 - 2.1mm / 5.5mm 25 - 2.5mm / 5.5mm
3	Input / Output (side 2)	P - straight plug A - angled plug S - socket
4	Plug / Socket dimensions (side 2)	T - tinned terminals 07 - 0.7mm / 2.35mm 13 - 1.3mm / 3.5mm 40 - 1.7mm / 4.0mm 48 - 1.7mm / 4.8mm 55 - 1.7mm / 5.5mm 21 - 2.1mm / 5.5mm 25 - 2.5mm / 5.5mm
5	cable type	C- YTLYek (coaxial) T- TLYP O- YTLY
6	wire diameter	035 - 0.35mm² 050 - 0.5mm² 075 - 0.75mm² 100 - 1.0mm²
7	length	025 - 250mm 300 - 3000mm
8	color	BK - black WH - white TR - transparent