


S/FTP Cat. 6A LSZH patch cord, blue, 30 m

PP6A-LSZHCU-B-30M

- Perfect connection
- Dual shielded for a reliable connection
- Low Smoke Zero Halogen (LSZH) jacket
- Gold plated contacts

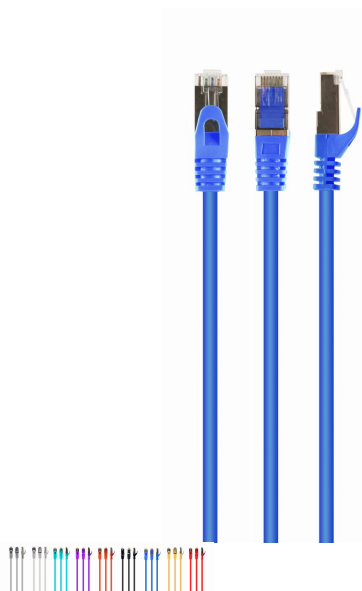

Features

- Patch cord with foil shielded pairs and braided cable, CAT 6A
- Gold plated contacts
- Low Smoke Zero Halogen (LSZH) jacket
- Molded strain reliefs
- Snagless boots

Packaging

Q'ty in crtn, pcs	10
Crtn volume, CUM	0.046
Crtn weight, kgs	12.8
Individual package size LxWxH:	270x200x50 mm
Carton size LxWxH:	410x310x360 mm
Country of origin	CN
Barcode	8716309125925
Customs code	8544421000

Specifications

Patch cord category 6A SSTP (shielded)
 Length: according to the item
 Structure: AWG 27 (7 x 0.135 mm wire), COPPER
 FM-PE insulation of the wire: 1.0 mm
 With LDPE filler
 With polyester tape
 With aluminum foil
 Drain hose: not used
 With Braid : 16 x 4/0.12mm
 Outer insulation: 5.8 mm
 Color: according to the item
 Operation up to 500 MHz

Certificates

