


MA-WA2-01

Adjustable wall 2-display mounting arm, 17"-27", up to 7 kg

- Position your screen perfectly
- Lightweight and tilting design

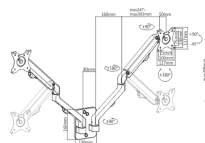

Features

- Monitor wall mount with double monitor arms
- Arms rotate, extend and retract, tilt to change reading angles, and allow to rotate displays from landscape-to-portrait mode, etc
- Enables easy ergonomic positioning for reduced strain
- Works with almost any LCD monitor (max. 27")
- Durable adjustable gas-springs suitable for monitors of 2-7 kg
- Built-in cable management for an organized and neat workspace
- VESA compatible (100 x 100 mm and 75 x 75 mm)

Packaging

Q'ty in crtn, pcs
Crtn volume, CUM
Crtn weight, kgs
Individual package size LxWxH:
Carton size LxWxH:
Country of origin
Barcode
Customs code

4
0.07236
17.5
385x240x170 mm
500x402x360 mm
CN
8716309126120
8302500000

Package contents

Wall arm
User manual
Mounting tools bag

Specifications

Material: plastic, steel, aluminum
Surface finish: powder coating
Color: fine texture black
Fit screen size: 17" 27"
Weight capacity (per screen): 2 ~ 7 kg
Vesa compatible: 100x100, 75x75 mm
Tilt range: +90° ~ -45°
Swivel range: +90° ~ -90°
Screen rotation: +180° ~ -180°
Installation: wall mounted
Cable management: yes

Certificates

