

6mm 2835 single color S Shape LED strip 60LEDs/m DC12V/DC24V



◆ Product Description :

S shape(zigzag) flex led strip with SMD2835 static color 60LEDs/m

1+2 OZ copper thickness FPC, 6mm PCB width

The biggest advantage is the S shape, which can be bend at any angle

Only available in IP20 non-waterproof version

Standard 5m per roll, the length also can be customized




◆ Product Datasheet


Product Number	S006060BB1LZ/S006060BC1LZ(S)	Luminance/M	W:515lm
Operating Voltage	DC12V/DC24V	Ra	80
Power/M	4.8W	Beam Angle	120°
SMD Type	2835	Size (mm)	5000x6mm
LED Qty/M	60	IP Rate	IP20
Color	W:3000K/4000K/6000K	Operation Temperature	- 25 ~ 60 °C
Pixel/M	/	Material	FPC
Control	/	Cutting Length	50mm/100mm
SDCM	< 5	Net Weight/Roll	/

◆ Outline Dimension (unit: mm)



DC24V

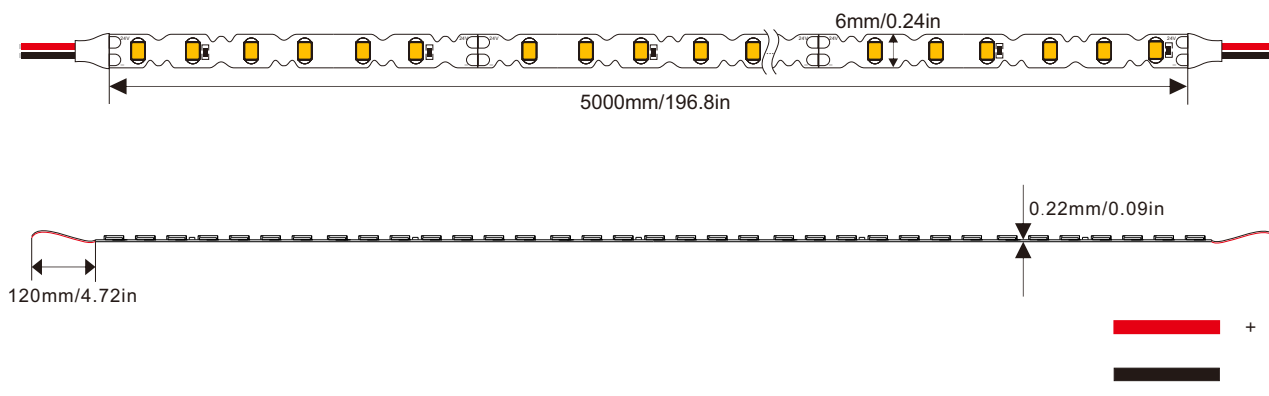

◆ SDCM comparison

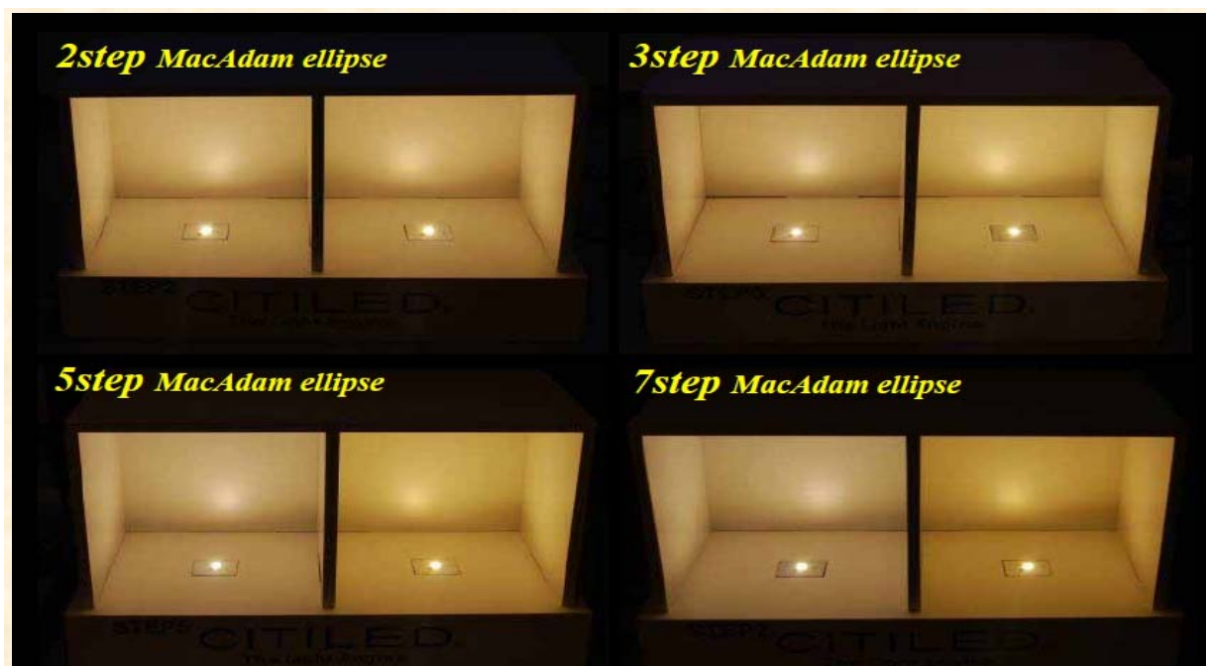


◆ Light distribution curve

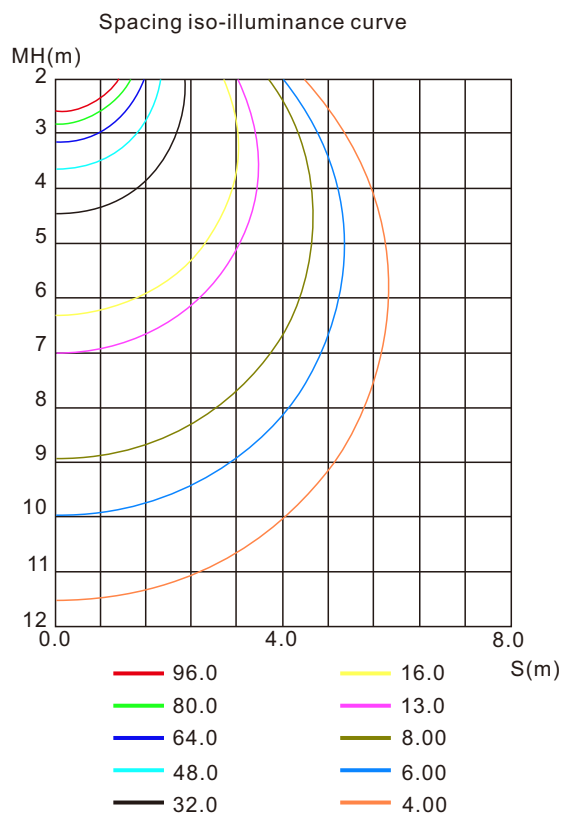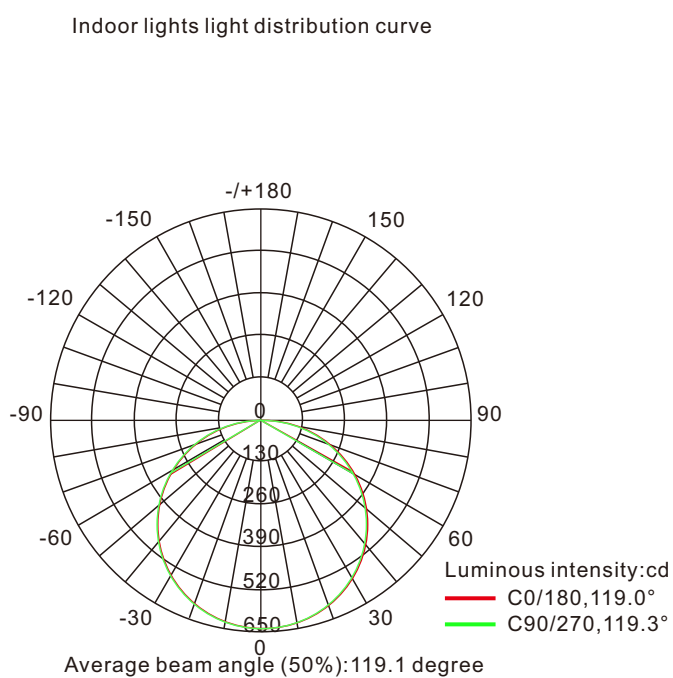

Note: The parameters are subject to change without notice!

◆ Wiring diagram

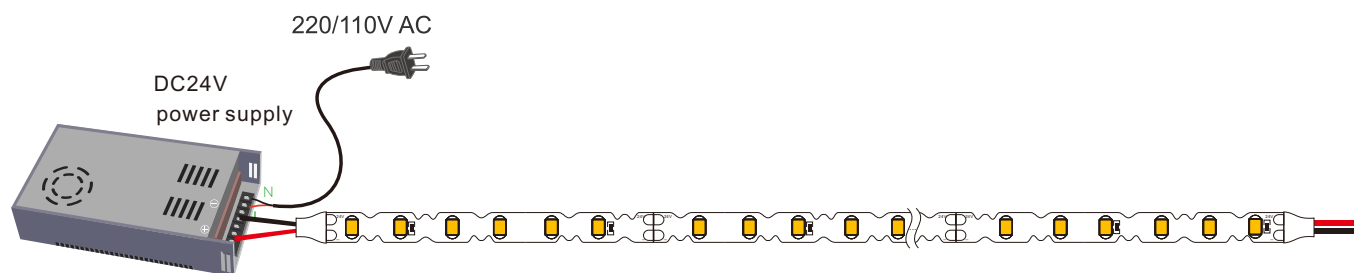

◆ Strip IP Rate



◆ Accessories



Screw



Silicone clip



End cap

◆ Schematic diagram of maximum bending prevention

