
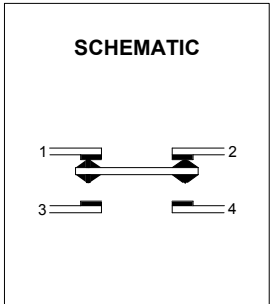


FOR 客户名称	APPROVED 客户确认签字	ATTN 销售负责人

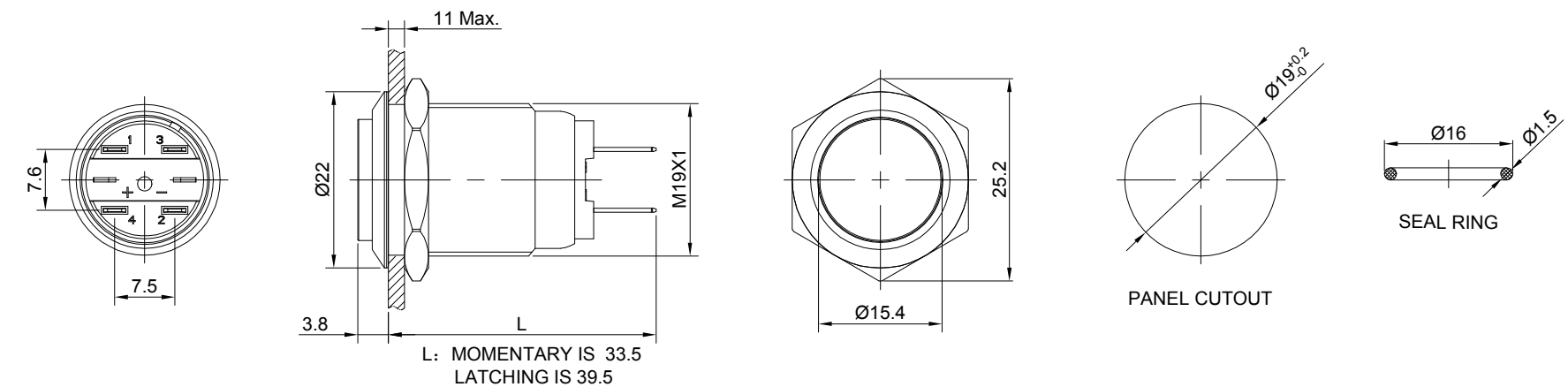

DOUBLE-BREAKPOINT SNAP-ACTION CONTACT SWITCH WITH FOUR TERMINALS

SPECIFICATIONS:

- 1.SWITCH RATING: U_i :250V, I_{th} :20A.
- 2.MECHANICAL LIFE: $\geq 1,000,000$ cycles.
- 3.ELECTRICAL LIFE: $\geq 50,000$ cycles.
- 4.INITIAL CONTACT RESISTANCE: $\leq 50m\Omega$.
- 5.INSULATION RESISTANCE: $\geq 100M\Omega$ (500VDC).
- 6.DIELECTRIC STRENGTH: 1,500V, RMS 50Hz, 1min.
- 7.OPERATING TEMPERATURE: $-25^{\circ}C \sim +55^{\circ}C$ (NO FREEZING, KEEP THE AIR FLOWING AROUND PUSHBUTTON).
- 8.OPERATING FORCE: ABOUT 4N(IP65), ABOUT 5N(IP67).
- 9.OPERATING TRAVEL: ABOUT 3mm.
- 10.TORQUE: 0.6Nm Max. APPLIED TO NUT.
- 11.FRONT PANEL PROTECTION DEGREE: IP65(IP67 MOMENTARY CAN BE CUSTOMIZED); IK09.
- 12.TERMINAL TYPE: PIN TERMINAL(2.8X0.5mm).
- 13.GENERAL TOLERANCE:0-18mm= ± 0.25 , 18-80mm= ± 0.52 .

MATERIALS:

- 1.CONTACT: SILVER ALLOY.
- 2.BUTTON: STAINLESS STEEL.
- 3.BODY: STAINLESS STEEL.
- 4.BASE: PC.

PART NUMBER: LAS1GQH-11■/S/※

"■"	OPERATION MODE	"※"	IP CLASS
NO LETTER	MOMENTARY	NO LETTER	IP65
Z	LATCHING	FP	IP67(MOMENTARY)

BRAND 品牌		红波按钮制造有限公司					
ONPOW 欧宝龙®							
		ONPOW PUSH BUTTON MANUFACTURE CO.,LTD.					
TITLE 名称	LAS1GQ SERIES ANTI-VANDAL PUSH BUTTON				UNIT 单位	mm	
DWG NO. 图号	LAS1GQH-11			SCALE 比例	1.2 : 1	SIZE 图纸	A4
FILE NAME 档案名称	LAS1GQ-11.DWG	DRAWN 制图	HCP 2023/10/27	SHEET 张	1/1	REV. 更改	1