

# High-current probe HSS-118 306 250 A 1504

Item HSS-118-0169



**ingun**<sup>®</sup>

Partner for Future Technology

## General data

|                                |                         |
|--------------------------------|-------------------------|
| Product group                  | High-current test probe |
| Sub-product group              | Standard HSS (press-in) |
| Series                         | HSS-118                 |
| Grid                           | 3 mm [118 mil]          |
| Contacting from                | Pin, Post, Flat contact |
| Magnetic                       | Yes                     |
| Installation type              | Plug-in                 |
| Quick-exchange system          | Yes                     |
| Adjustable installation height | No                      |
| Non-rotating                   | No                      |
| Compatible receptacle(s)       | KS-112                  |
| Min. temperature               | - 100 °C [- 212 °F]     |
| Max. temperature               | + 200 °C [+ 392 °F]     |
| RoHS-compliant                 | RoHS-3;6c               |

## Electrical data


|                                       |          |
|---------------------------------------|----------|
| Current load capacity / rated current | 20 A     |
| Typical resistance (Ri)               | <10 mOhm |

## Mechanical data

|                                |                   |
|--------------------------------|-------------------|
| Total length                   | 34.3 mm [1.35 in] |
| Barrel diameter                | 1.66 mm [.065 in] |
| Maximum stroke                 | 5.3 mm [.208 in]  |
| Spring pre-load                | 0.5 N [1.79 ozf]  |
| Collar height                  | 04                |
| Spring force at working stroke | 1.5 N [5.39 ozf]  |
| Recommended working stroke     | 4 mm [.157 in]    |

## Tip style data

|                    |                  |
|--------------------|------------------|
| Tip style          | 06 serrated      |
| Tip diameter       | 2.5 mm [.098 in] |
| Tip style surface  | A gold           |
| Tip style material | 3 CuBe           |

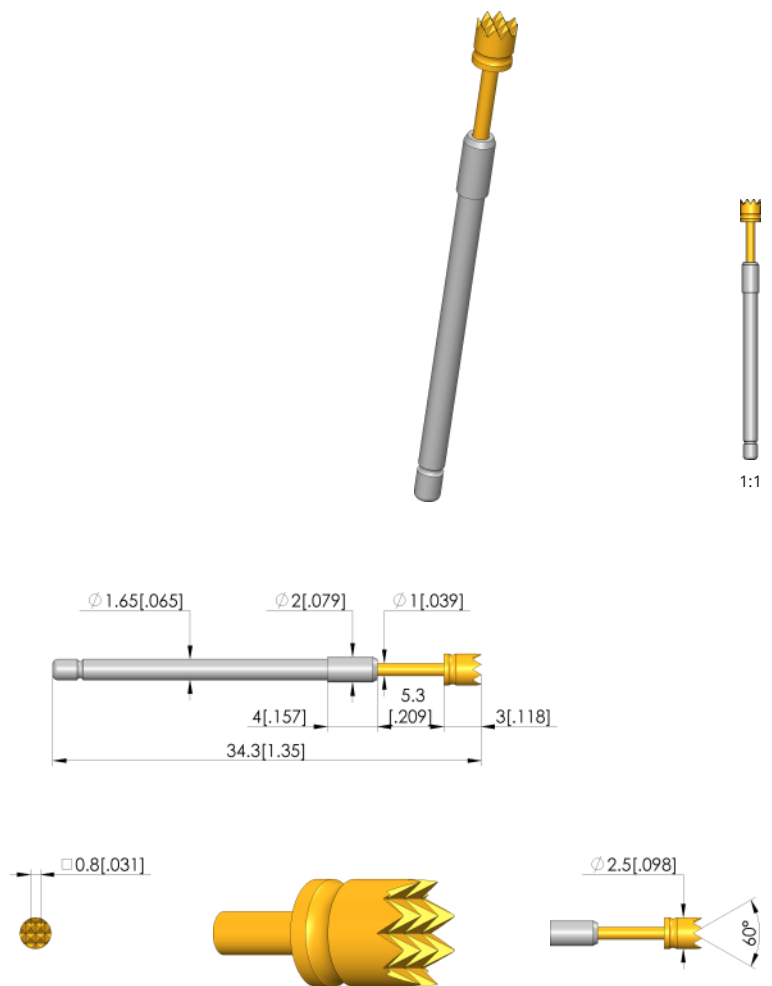

1:1

HIGH-CURRENT TEST PROBE

# High-current probe

## HSS-118 306 250 A 1504

Item HSS-118-0169



**ingun**<sup>®</sup>  
Partner for Future Technology



### INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162  
78467, Constance, Germany  
Phone +49 7531 8105-0  
Customer hotline +49 7531 8105-888  
Fax +49 7531 8105-65  
info@ingun.com



Prices and delivery times on request.  
Technical changes reserved. 11/23 EN

Learn more about  
High-current test probe



HIGH-CURRENT TEST PROBE

ingun.com