

Test plug PS-SATA3.0-M-007-G5-B

Item 106534



GO TO PRODUCT

ingun[®]

Partner for Future Technology

General data

Product group	PS test plug
Series	PS
Sub-series	PS-SATA
Grid	20 mm [787 mil]
DUT / contact	SATAsocket
DUT interface gender	F signal conductor female / socket
Width	19.6 mm [.771 in]
Height	11.4 mm [.448 in]
Min. temperature	- 20 °C [- 68 °F]
Max. temperature	+ 75 °C [+ 167 °F]
RoHS-compliant	RoHS-3;6c

Inner conductor data


Number of inner conductors	7
----------------------------	---

Electrical data

Impedance	100 Ohm
Max. data rate	1.2 Gbit/s

Mechanical data

Total length	28 mm [1.10 in]
--------------	-----------------

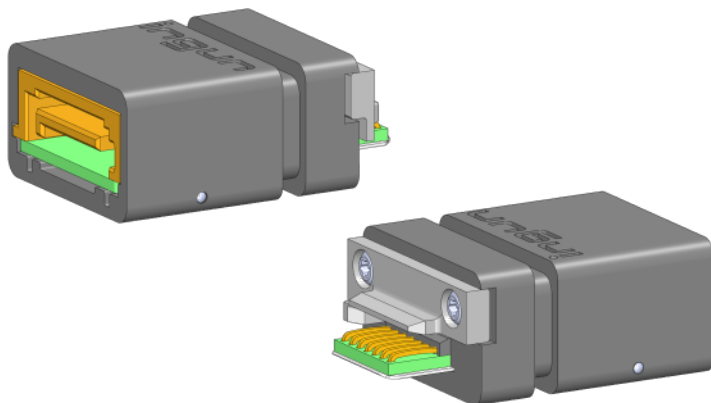

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 11/23 EN

Learn more about
Test probes

