

Test plug

PS-USB-Micro-B-005-F7,6

Item 34816



ingun[®]
Partner for Future Technology

- Signal transmission via original connector plug or solder connection
- Optional spring elements (112863: set of 2) can compensate for tolerances of ± 0.4 mm and positioning inaccuracies.

General data


Product group	PS test plug
Series	PS
Sub-series	PS-USB
Grid	14.5 mm [570 mil]
DUT / contact	USB MICRO Type B
DUT interface gender	F signal conductor female / socket
KS sub-series	PSA-F7,6
Width	7.6 mm [.299 in]
Height	11.9 mm [.468 in]
Min. temperature	- 80 °C [- 176 °F]
Max. temperature	+ 150 °C [+ 302 °F]
RoHS-compliant	RoHS-3

Inner conductor data

Inner conductor max. current load capacity	1 A
Number of inner conductor poles	5

Mechanical data


Total length	25 mm [.984 in]
--------------	-----------------

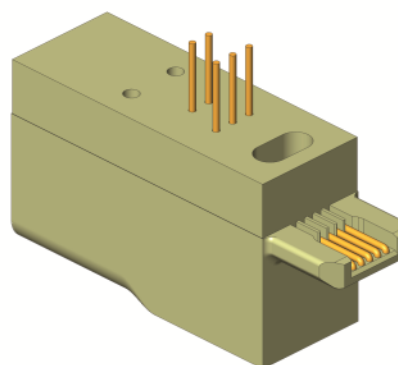

Test plug
PS-USB-Micro-B-005-F7,6
Item 34816



ingun[®]
Partner for Future Technology

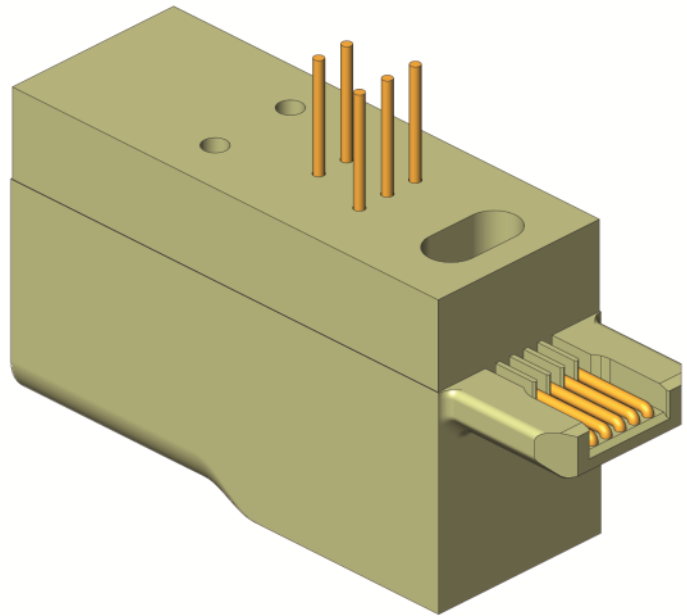

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 12/23 EN

Learn more about
Test probes

