

Test plug PS-RJ12-M-006-M3-B

Item 53767



ingun[®]


Partner for Future Technology

- Precise, low-wear contacting of RJ plug connectors
- Outstanding service life: up to 250,000 cycles under optimal conditions.
- Reliable data transmission
- Installation via optional floating mount
- Signal transmission via original connector plug

INGUN SELECTION

General data

Product group	PS test plug
Series	PS
Sub-series	PS-RJ
DUT / contact	RJ-12
DUT interface gender	F signal conductor female / socket
Width	11.6 mm [.456 in]
Height	8.4 mm [.330 in]
RoHS-compliant	-

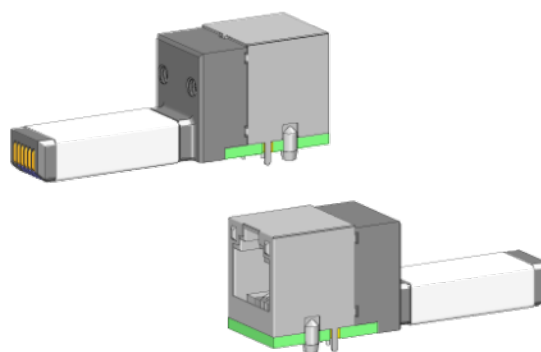

Inner conductor data

Number of inner conductor poles	8
---------------------------------	---

Electrical data

Max. data rate	1 Gbit/s
----------------	----------

Mechanical data

Total length	42 mm [1.65 in]
--------------	-----------------

Test plug


PS-RJ12-M-006-M3-B

Item 53767



ingun[®]



Partner for Future Technology

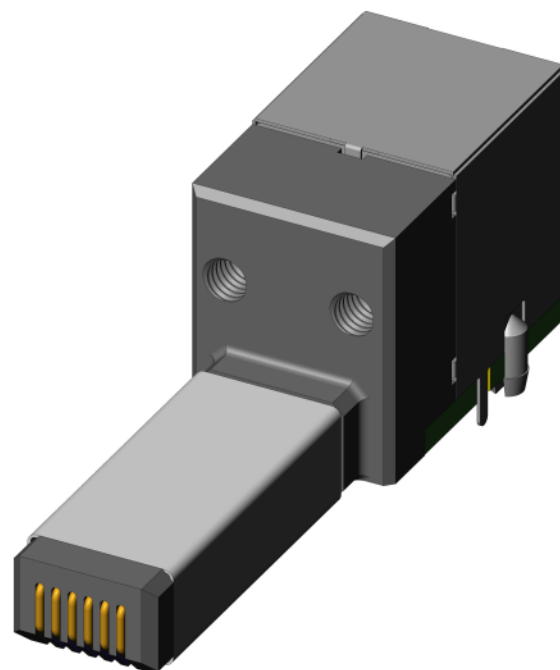

Test plug
PS-RJ12-M-006-M3-B
Item 53767



ingun[®]
Partner for Future Technology

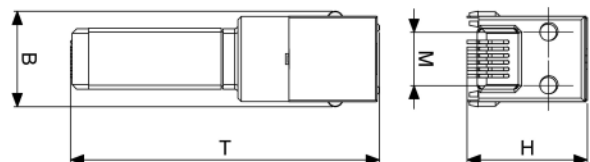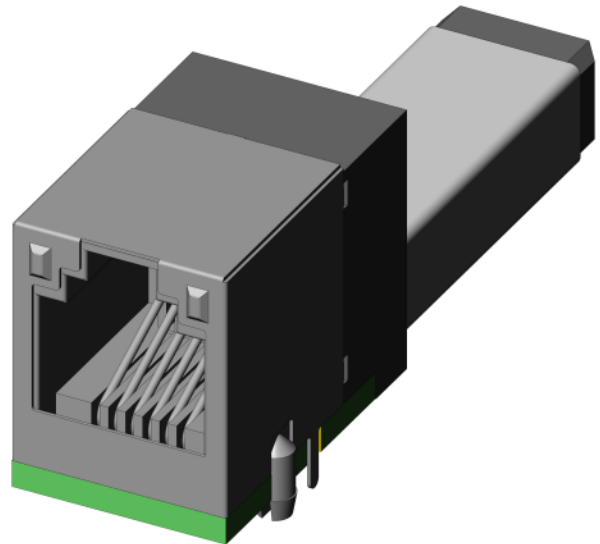

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 12/23 EN

Learn more about
Test probes

