


Masking cover MP-22

Ref. C28261L01_0.25, C28261L10_0.25, C28261L07_0.25

Ref. arch 17167, 17167L9010, 17167L9005

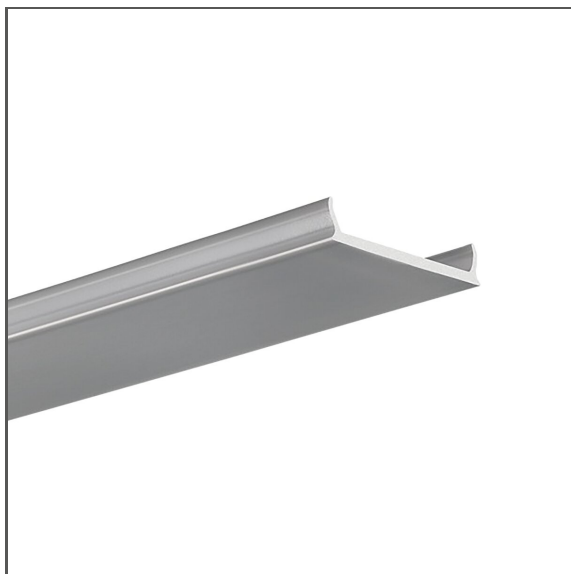

- Masking the electronics installed in the profiles
- Creating an installation with a dashed line of light

 
APPLICATION

- capping the lighting fixture on sections without a light source

MOUNTING

- to the profile, by pressing

TECHNICAL DRAWING



TECHNICAL SPECIFICATIONS

Material	PC	Color	Length	Ref
		■ gray metalized	1000 mm	C28261L01_1 17167_1
			250 mm	C28261L01_0.25 17167_0.25
		□ white lacquered	1000 mm	C28261L10_1 17167L9010_1
			250 mm	C28261L10_0.25 17167L9010_0.25
		■ black lacquered	1000 mm	C28261L07_1 17167L9005_1
			250 mm	C28261L07_0.25 17167L9005_0.25

Masking cover MP-22

Ref. C28261L01_0.25, C28261L10_0.25, C28261L07_0.25

Ref. arch 17167, 17167L9010, 17167L9005

RELATED PROFILES > ARCHITECTURAL



GIZA
A05556
Ref. arch B5556



GIZA-DUO-LL
A02162
Ref. arch C2162



GIZA-LL
A00758
Ref. arch C0758



GIZA-LL-T
A02479
Ref. arch C2479




GIZA-LL-UST
A02724N
Ref. arch C2724



GLAZA-DUO
A03059
Ref. arch C3059




GLAZA-LL
A02627
Ref. arch C2627

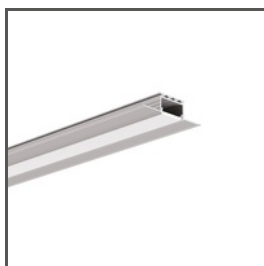

KOZUS
A07823
Ref. arch B7823



KOZUS-CR
A00600
Ref. arch C0600

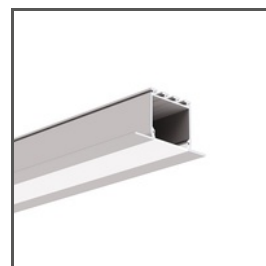


LARKO
A05552
Ref. arch B5552



LIPOD
A05554
Ref. arch B5554



LOC-30
A18015
Ref. arch 18015

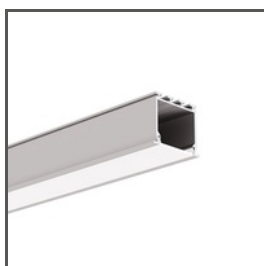


LOKOM
A05553
Ref. arch B5553



OPAC-30
A06164
Ref. arch B6164

RELATED PROFILES > FOR SCONCES AND WALL LIGHTING

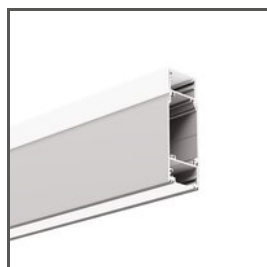

KIDES-DUO
A18032
Ref. arch 18032



WERKIN
A18025
Ref. arch 18025

RELATED PROFILES > STAIRS ILLUMINATION

Masking cover MP-22

Ref. C28261L01_0.25, C28261L10_0.25, C28261L07_0.25

Ref. arch 17167, 17167L9010, 17167L9005



STEPUS

A18038

Ref. arch 18038