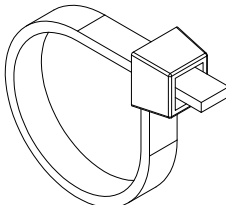
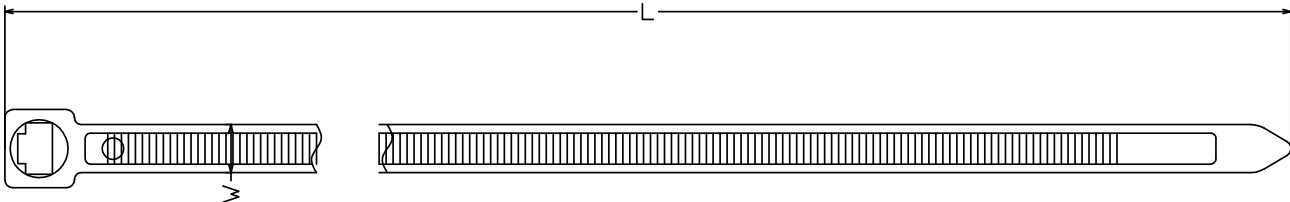


	G	F	E	D	C	B	A													
1	ITEM: FIX-S-9.0X600/N							1												
2								2												
3								3												
4								4												
5	NOTE: TEMPURATURE RANGE: -40C TO +85C (-40F TO 185F) INCH TOLERANCE UNLESS OTHERWISE SPECIFIED: .X X ± . 015 . XXX± .005 ANGULAR± 1. MILLIMETER TOLERANCE UNLESS OTHERWISE SPECIFIED: ° 1.0 ± . 2. 10.0 - 30 ± .35 • ABOVE 30 ± .5 <table><tr><td>MATERIAL:</td><td>ASCEND PA66 FOR ALL COLOR PRODUCTS</td></tr><tr><td>LEMGTH:</td><td>600MM (23.62 inch)</td></tr><tr><td>WIDTH:</td><td>9.0MM (0.35 inch)</td></tr><tr><td>THINKNESS:</td><td>1.75MM (0.068 inch)</td></tr><tr><td>TENSILE STR.</td><td>180lbf / 800N / 81.57 kgf</td></tr><tr><td colspan="2">SHANGHAI XINLONG PLASTIC MANUFACTURING CO., LTD</td></tr></table>							MATERIAL:	ASCEND PA66 FOR ALL COLOR PRODUCTS	LEMGTH:	600MM (23.62 inch)	WIDTH:	9.0MM (0.35 inch)	THINKNESS:	1.75MM (0.068 inch)	TENSILE STR.	180lbf / 800N / 81.57 kgf	SHANGHAI XINLONG PLASTIC MANUFACTURING CO., LTD		5
MATERIAL:	ASCEND PA66 FOR ALL COLOR PRODUCTS																			
LEMGTH:	600MM (23.62 inch)																			
WIDTH:	9.0MM (0.35 inch)																			
THINKNESS:	1.75MM (0.068 inch)																			
TENSILE STR.	180lbf / 800N / 81.57 kgf																			
SHANGHAI XINLONG PLASTIC MANUFACTURING CO., LTD																				
6								6												
	G	F	E	D	C	!	