


DIGITUS Mini DisplayPort - HDMI Adapter / Converter

AK-340411-001-W
EAN 4016032328599

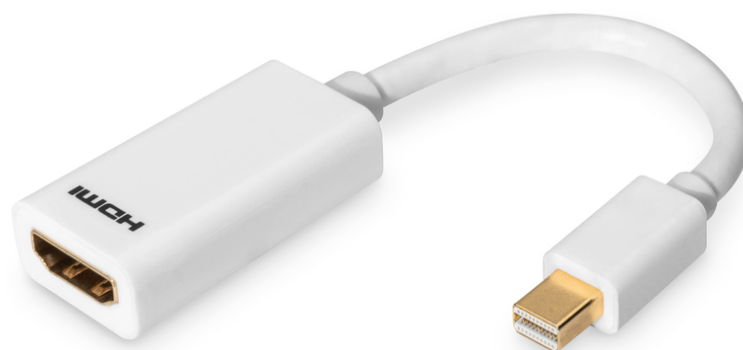

DisplayPort adapter cable, mini DP - HDMI type A M/F, 0.15m, DP 1.1a compatible, wh

This digital HD video and audio adapter / converter suits for example ideal to connect a MacBook®, MacBook Air®, MacBook Pro®, iMac®, Mac Mini® and Mac Pro® to a HDMI Monitor, beamer, LCD/TFT monitor, LED or plasma TV with a HDMI cable.

Ensures a lower burden of the interface.

- Max. supported Video Resolution: 1920 x 1080 p with 60 Hz
- Supported transmission modes: RBR, HBR, HBR2
- Maximal bandwidth: 10,8 Gbps
- HBR-Version/transfer mode: HBR1 (2,70 Gbit/s per lane)
- HDCP-Version: HDCP 1.3

- Assortment: DisplayPort Cables
- Color cable: white
- Color connector: white
- Connector 1: Mini DP, plug
- Connector 2: HDMI type A, jack
- Connector surface: nickel-plated
- DisplayPort standard: DisplayPort 1.1a
- HDTV Resolution max.: 1920 x 1080 Pixel, 60Hz
- HDTV Standard: Full HD
- Hoods: molded
- Interlock: none
- Length: 0.15 m
- AOC - Active Optical Cable: no

Logistics

	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	100	4.30	50.00	33.00	22.00	36,300.00
Packaging Unit Inside	10	0.43	1.00	16.00	24.00	384.00
Packaging Unit Single	1	0.04	1.00	16.00	24.00	384.00
Net single without Packaging	1	0.04	1.00	16.00	24.00	384.00

More images:

