



HQS-6W-60LED-WW-WP-24V

Professional Led Strip, 6 W/m



■ Features:

- Double copper layer
- Can be cut every segment 10 cm
- 3 years warranty

3000K
WARM WHITE

IP 64

CRI>80

120°
lens

UK
CA

CE

3
year warranty


TECHNICAL DETAILS

MODEL	HQS-6W-60LED-WW-WP-24V	EPREL
Supply voltage	24V $\pm$ 0.5Vdc	
Power	6W/m (30W/reel)	
Current	0.25 A/m (1.25A/roll)	
Power per reel	30W	
Color temperature	3000K	
Beam angle	120°	
Luminous flux	620 lm/m (3010lm/roll)	
CRI	>80	
Maximum length for one sided supply	5m	
IP protection degree	IP64	
Working temperature	-25°C ÷ 50°C	
Storage temperature	-30°C ÷ 60°C	
LED QTY	60 LEDs/m (300 LEDs/reel)	
Width PCB	8mm	
Cut section	100mm	
Connection wire	2 x AWG20 (0.52 mm ²) stranded wire, length = 140 mm: V+: red: V-:black.	
Dimensions (L x W x H)	5000 x 8 x 1.2 mm	
Packing	5m / reel (bag)	



MW LIGHTING

HQS-6W-60LED-WW-24V

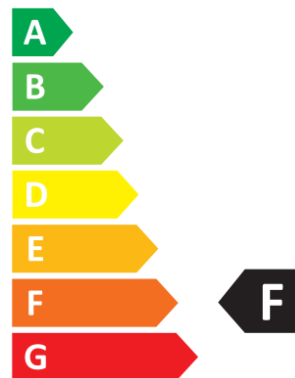

3
kWh/1000h



2019/2015

MECHANICAL SPECIFICATION:

