



HQS-6W-60LED-W-24V

Professional Led Strip, 6 W/m



6500K
WHITE

■ Features:

- Double copper layer

Can be cut every segment 10 cm

- 3 years warranty

IP33

CRI>80

120°
lens

UK
CA

CE

3


year warranty

TECHNICAL DETAILS

MODEL	HQS-6W-60LED-W-24V	EPREL
Supply voltage	24V $\pm$ 0.5Vdc	
Power	6W/m (30W/reel)	
Current	0.25 A/m (1.25A/roll)	
Power per reel	30W	
Color temperature	6500K	
Beam angle	120°	
Luminous flux	660 lm/m (3010lm/roll)	
CRI	>80	
Maximum length for one sided supply	5m	
IP protection degree	IP33	
Working temperature	-25°C ÷ 50°C	
Storage temperature	-30°C ÷ 60°C	
LED QTY	60 LEDs/m (300 LEDs/reel)	
Width PCB	8mm	
Cut section	100mm	
Connection wire	2 x AWG20 (0.52 mm ²) stranded wire, length = 140 mm: V+: red: V-:black.	
Dimensions (L x W x H)	5000 x 8 x 1.2 mm	
Packing	5m / reel (bag)	



MW LIGHTING
HQS-6W-60LED-W-24V

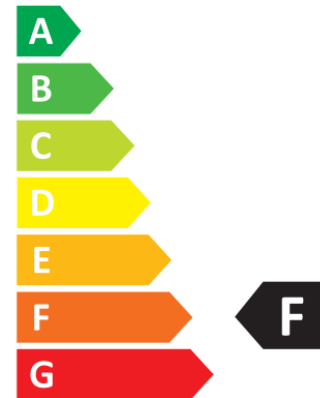

3
kWh/1000h



2019/2015

MECHANICAL SPECIFICATION:

