



HQS-9.6W-120LED-NW-WP-12V

Professional Led Strip, 9.6 W/m



■ Features:

- Double copper layer
- Can be cut every segment 2.5 cm
- 3 years warranty

4000K
NEUTRAL WHITE

IP 64

CRI>80




TECHNICAL DETAILS

MODEL	HQS-9.6W-120LED-NW-WP-12V	EPREL
Supply voltage	12V $\pm$ 0.5Vdc	
Power	9.6W/m (48W/reel)	
Current	0.8 A/m (4A/roll)	
Power per reel	48W	
Color temperature	4000K	
Beam angle	120°	
Luminous flux	1040 lm/m (5200lm/roll)	
CRI	>80	
Maximum length for one sided supply	5m	
IP protection degree	IP64	
Working temperature	-25°C ÷ 50°C	
Storage temperature	-30°C ÷ 60°C	
LED QTY	120 LEDs/m (600 LEDs/reel)	
Width PCB	8mm	
Cut section	25mm	
Connection wire	2 x AWG20 (0.52 mm ²) stranded wire, length = 140 mm: V+: red: V-:black.	
Dimensions (L x W x H)	5000 x 8 x 1.2 mm	
Packing	5m / reel (bag)	



MW LIGHTING
HQS-9.6W-120LED-NW-WP-12V

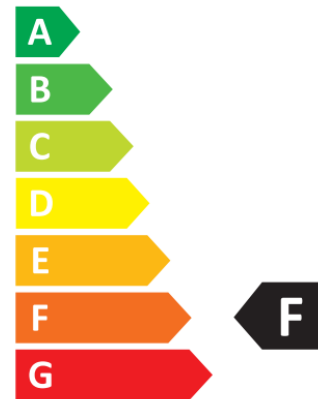

5
kWh/1000h



2019/2015

MECHANICAL SPECIFICATION:

