



MW-MLD-HE-2NW-LENS170

Professional Led Modules; **4-8cm** 3D letters, lightboxes



■ Features:

- luminous efficacy 118 lm/W
- for indoor and outdoor use
- 30 pcs in chain

UK
CA

CE

TECHNICAL DETAILS



MODEL	MW-MLD-HE-2NW-LENS170
Supply voltage	12V DC
Power consumption per module	0.72W
Chain power consumption	21.6W
Current consumption per module	60mA
LED diodes	San'an led - 2835
Quantity of LEDs	2
Light color	Neutral White (~4000K)
Luminous flux	85lm
Luminous flux density	118lm/W
Color rendering index - CRI	≥80
Beam angle	170°
Current stabilization	Yes
Dimming	Yes
Module dimensions (L x W x H)	51 x 15 x 11mm
Cable length	99.5mm
Number of modules in 1m	6.7
Box weight	17.6kg
Packing	Chain – 30pcs / Bag – 150pcs / Box – 1500pcs
Montage	Adhesive tape / mounting screw
Lifetime	L70B50 > 50000h
Working temperature	-25°C ÷ 55°C
IP protection	IP67
Warranty	7 years




MW-MLD-HE-2NW-LENS170

Professional Led Modules; **4-8cm** 3D letters, lightboxes



Dimensions

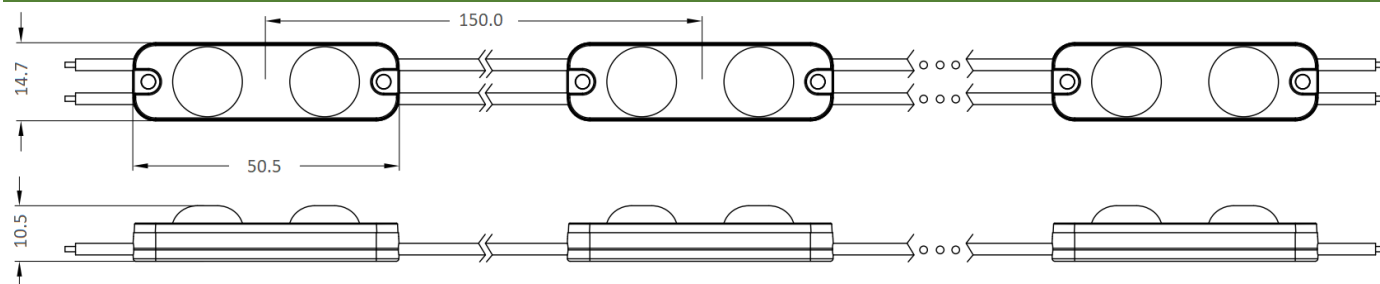

Connection diagram

One-side power input:



Maximum number of modules 30 pcs

Two-side power input:




Maximum number of modules 60 pcs

It is acceptable to connect multiple chains in parallel, as long as the power supply provides sufficient power

Light color / CCT

Light color

Neutral White (~7000K)

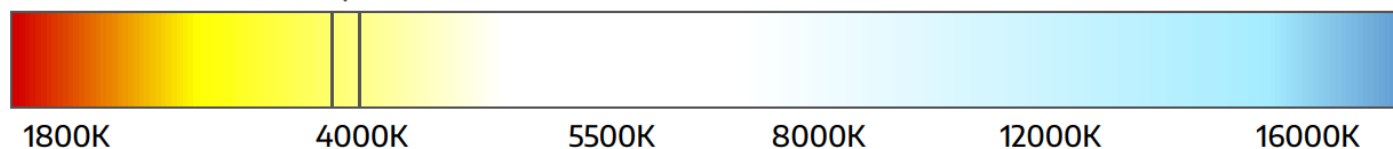

Energy label / Beam angle

