


Eye bolts

BN 2851

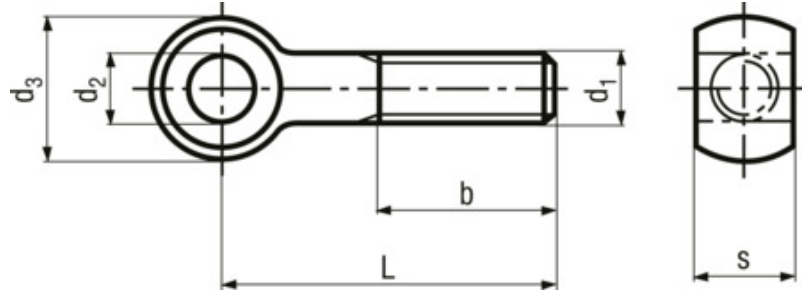

Standard **DIN 444 B**, ~UNI 6058, ~ČSN 021167

Thread partially threaded

Material Stainless steel

Material type A2

Article no.	d1	L	d2 H9	d3 max.	s max.	b
1491121	M6	30	6	14	7	18
1491148	M6	40	6	14	7	18
1491172	M6	50	6	14	7	18
1491202	M6	60	6	14	7	18
1491210	M8	30	8	18	9	22
1491229	M8	40	8	18	9	22
1491237	M8	50	8	18	9	22
1491245	M8	60	8	18	9	22
1491253	M8	70	8	18	9	22
1491261	M8	80	8	18	9	22
1491288	M8	100	8	18	9	22
1491296	M10	30	10	20	12	26
1491318	M10	40	10	20	12	26
1491326	M10	50	10	20	12	26
1491334	M10	60	10	20	12	26
1491342	M10	70	10	20	12	26
1491350	M10	80	10	20	12	26
1491369	M10	100	10	20	12	26
1491377	M12	50	12	25	14	30
1491385	M12	60	12	25	14	30
1491393	M12	70	12	25	14	30
1491407	M12	80	12	25	14	30

Article no.	d1	L	d2 H9	d3 max.	s max.	b
1491415	M12	100	12	25	14	30
1491423	M12	120	12	25	14	30
1491431	M16	60	16	32	17	38
1491458	M16	70	16	32	17	38
1491466	M16	80	16	32	17	38
1491474	M16	100	16	32	17	38
1491482	M16	120	16	32	17	38
1491601	M16	140	16	32	17	44
1491652	M16	150	16	32	17	44
1491717	M20	80	18	40	22	46
1492020	M20	100	18	40	22	46
1492438	M20	120	18	40	22	46
1492586	M20	140	18	40	22	52
1492705	M20	150	18	40	22	52
1493337	M20	180	18	40	22	52