


DIGITUS VGA Monitor Connection Cable

AK-310103-030-E
EAN 4016032286684

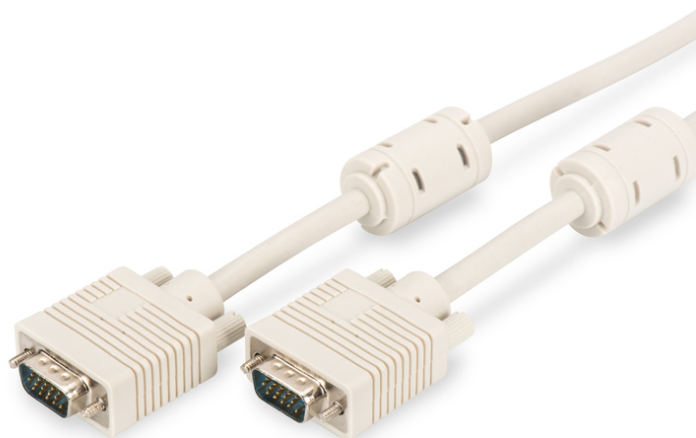

VGA Monitor connection cable, HD15 M/M, 3.0m, 3Coax/7C, 2xferrite, be

For connection of a PC, for example, with a monitor or beamer /projector.

Offers high-quality protection against external interferences and prevents ghost images and other image faults.

- Support 1280 x 1024 pixel with 60Hz
- 3 x Coax for RGB and 7 x AWG28 signal wires
- 2 x ferrite filters
- Assortment: VGA Cables
- AWG: 28
- Cable type: 3Coax + 7-wire

- Color cable: beige
- Color connector: beige
- Connector 1: HD DSUB, 15-pin, plug
- Connector 2: HD DSUB, 15-pin, plug
- Connector surface: nickel-plated
- Display Data Channel: DDC2
- Ferrite filter: 2 x ferrite beads
- Hoods: molded
- Packaging: Polybag
- Wire material: CU
- Length: 3 m
- Shielding: Double shielding

Logistics						
	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm ³
Packaging Unit Carton	30	10.50	39.00	31.00	24.00	29,016.00
Packaging Unit Inside	10	3.50	15.00	31.00	31.00	14,415.00
Packaging Unit Single	1	0.35	23.00	18.00	4.50	1,863.00
Net single without Packaging	1	0.34	23.00	18.00	4.50	1,863.00