


DIGITUS VGA Monitor Extension Cable

AK-310203-018-E
EAN 4016032287087

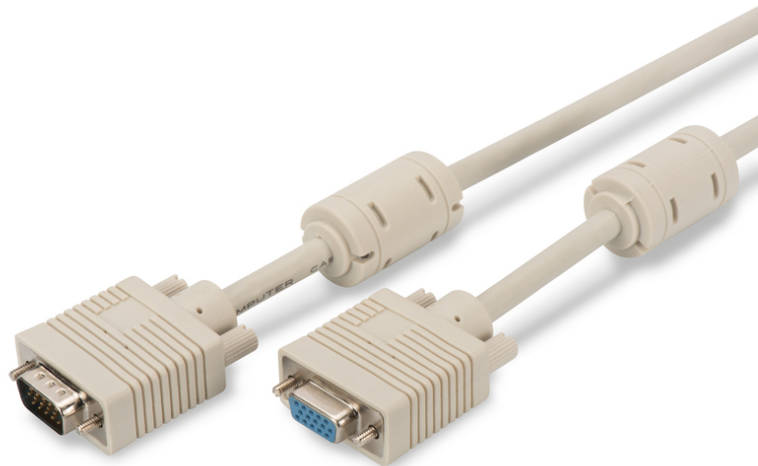

VGA Monitor extension cable, HD15 M/F, 1.8m, 3Coax/7C, 2xferrite, be

For extension of monitor cables or devices (with HD15 plug), for example, PC, monitor or beamer / projector.

Offers high-quality protection against external interferences and prevents ghost images and other image faults.

- Support 1024 x 768 pixel with 60Hz
- Assortment: VGA Cables
- AWG: 28
- Cable type: 3Coax + 7-wire

- Connector 1: HD DSUB, 15-pin, plug
- Connector 2: HD DSUB, 15-pin, jack
- Connector surface: nickel-plated
- Display Data Channel: DDC2
- Ferrite filter: 2 x ferrite beads
- Hoods: molded
- Packaging: Polybag
- Wire material: CU
- Length: 1.8 m
- Shielding: Double shielding

Logistics						
	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	40	9.50	45.00	33.00	26.00	38,610.00
Packaging Unit Inside	10	2.38	38.00	30.00	10.00	11,400.00
Packaging Unit Single	1	0.24	15.00	18.00	4.00	1,080.00
Net single without Packaging	1	0.23	15.00	18.00	4.00	1,080.00