


DIGITUS VGA Monitor Extension Cable

AK-310203-150-E
EAN 4016032287131

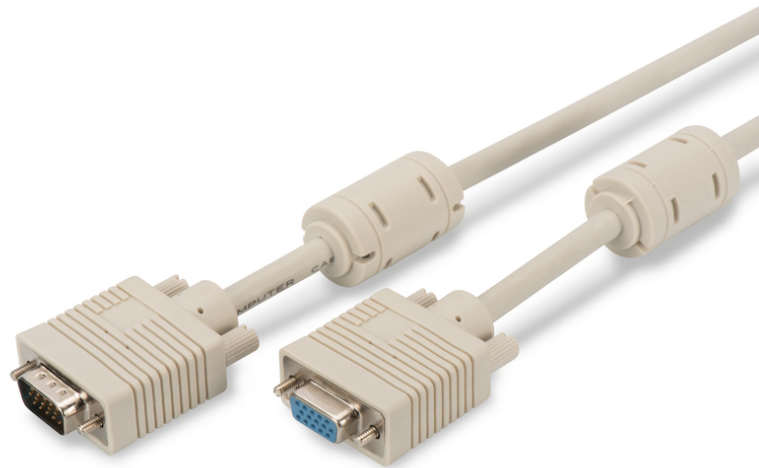

VGA Monitor extension cable, HD15 M/F, 15.0m, 3Coax/7C, 2xferrite, be

For extension of monitor cables or devices (with HD15 plug), for example, PC, monitor or beamer / projector.

Offers high-quality protection against external interferences and prevents ghost images and other image faults.

- Support 1280 x 1024 pixel with 60Hz
- 3 x Coax for RGB and 7 x AWG28 signal wires
- 2 x ferrite filters
- Assortment: VGA Cables
- AWG: 28

- Cable type: 3Coax + 7-wire
- Connector 1: HD DSUB, 15-pin, plug
- Connector 2: HD DSUB, 15-pin, jack
- Connector surface: nickel-plated
- Display Data Channel: DDC2
- Ferrite filter: 2 x ferrite beads
- Hoods: molded
- Packaging: Polybag
- Wire material: CU
- Length: 15 m
- Shielding: Double shielding

Logistics						
	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	10	10.00	38.50	31.00	31.00	36,998.50
Packaging Unit Inside	1	1.00	38.00	30.00	31.00	35,340.00
Packaging Unit Single	1	1.00	30.00	35.00	10.00	10,500.00
Net single without Packaging	1	0.98	30.00	35.00	10.00	10,500.00