


DIGITUS DisplayPort Adapter Cable

AK-340301-030-S
EAN 4016032289128

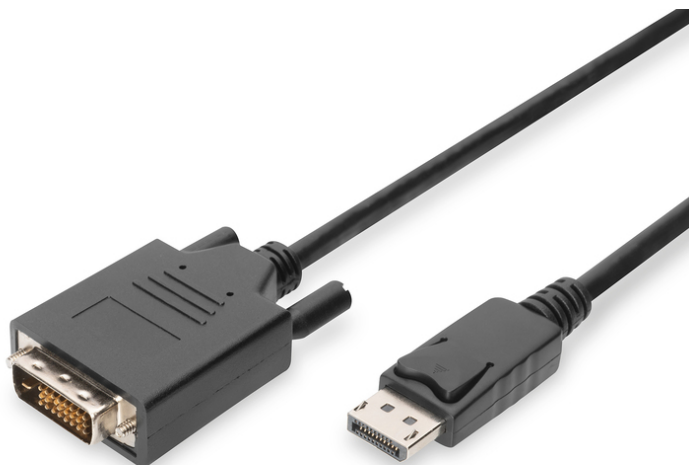

DisplayPort adapter cable, DP - DVI (24+1) M/M, 3.0m, w/interlock, DP 1.1a compatible, bl

This digital HD cable converts DisplayPort signals to DVI signals and is ideal to connect DisplayPort devices to your HD TV, beamer or monitor with DVI interface.

Full HD resolution of up to 1080p

- Support up to 1080p with 60Hz
- Copper wire, foil and braid shielding for robustness and reliable connection
- Plug and play, no additional driver needed
- Supported transmission modes: RBR, HBR, HBR2
- Maximal bandwidth: 10,8 Gbps
- HBR-Version/transfer mode: HBR1 (2,70 Gbit/s per lane)
- HDCP-Version: HDCP 1.3
- Assortment: DisplayPort Cables

- AWG: 30
- Color cable: black
- Color connector: black
- Connector 1: DP, plug
- Connector 2: DVI-D, (24+1), plug
- Connector surface: nickel-plated
- DisplayPort standard: DisplayPort 1.1a
- Ferrite filter: none
- HDTV Standard: Full HD
- Hoods: molded
- Interlock: Snap fastener
- Packaging: Polybag
- Wire material: CU
- Length: 3 m
- AOC - Active Optical Cable: no
- Shielding: Double shielding

Logistics

	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm ³
Packaging Unit Carton	60	10.00	50.00	32.00	22.00	35,200.00
Packaging Unit Inside	10	1.67	22.00	15.00	3.50	1,155.00
Packaging Unit Single	1	0.17	2.80	17.00	24.50	1,166.20
Net single without Packaging	1	0.16	2.80	17.00	24.50	1,166.20

More images:

