

DIGITUS Fiber Optic Multimode Patch Cord, OM4, SC / SC

DK-2522-03-4
EAN 4016032308874



FO patch cord, duplex, SC to SC MM OM4 50/125 µ, 3 m

FO patch cord, duplex, SC to SC, MM OM4 50/125 µ, 3 m

Future-oriented standards and high-end quality for your network.



- Duplex cable
- Connector with ceramic ferrule
- Cable diameter 3 mm
- Single packed with test-report
- Color: RAL 4003
- Assortment: Fiber Optic Patch Cables
- Boot: two-color

- Cable diameter: 3 mm
- Cable jacket: LSOH
- Cable type: I-VH 2G50/125µ
- Connector 1: SC
- Connector 2: SC
- Fiber class: OM4
- Fiber diameter: 50/125µ
- Mode: Multimode
- Packaging: DIGITUS Polybag
- Length: 3 m

Logistics

	Number (pcs)	Weight (kg)	Depth (cm)	Width (cm)	Height (cm)	cm³
Packaging Unit Carton	120	8.90	41.00	41.00	28.00	47,068.00
Packaging Unit Inside	15	1.11	19.00	19.00	12.00	4,332.00
Packaging Unit Single	1	0.07	17.00	17.00	1.00	289.00
Net single without Packaging	1	0.07	17.00	17.00	1.00	289.00

More images:

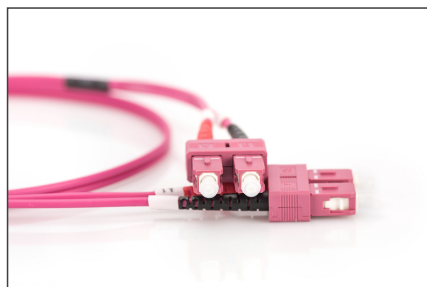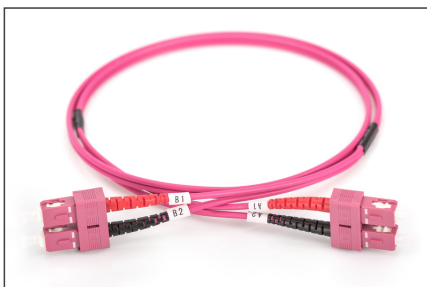

Part No.	DK-2522-03-4			
Length	3 m			
Cable Type	Duplex MM 50/125		OM4 LSZH	
	END A		END B	
Connector Type	SC		SC	
Insertion Loss (dB)	0.11	0.05	0.11	0.11
Return Loss (dB)	30.5	32	33.2	35.8
Q.C.	PASS			

