



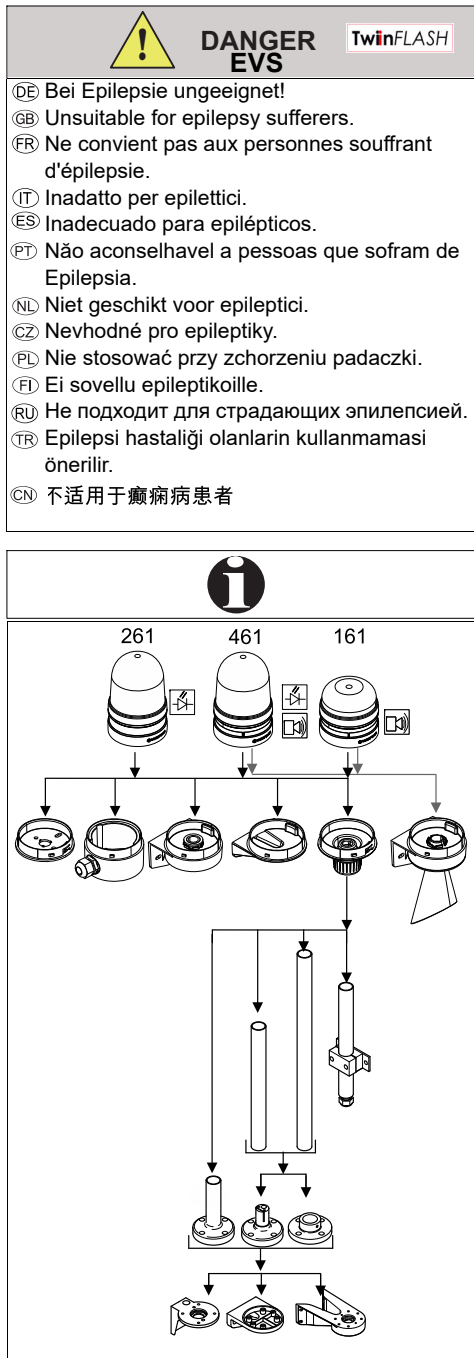

WERMA Signaltechnik GmbH + Co. KG
D-78604 Rietheim-Weilheim
Telefon +49 (0)7424 / 9557-0
Telefax +49 (0)7424 / 9557-44
info@werma.com
www.werma.com

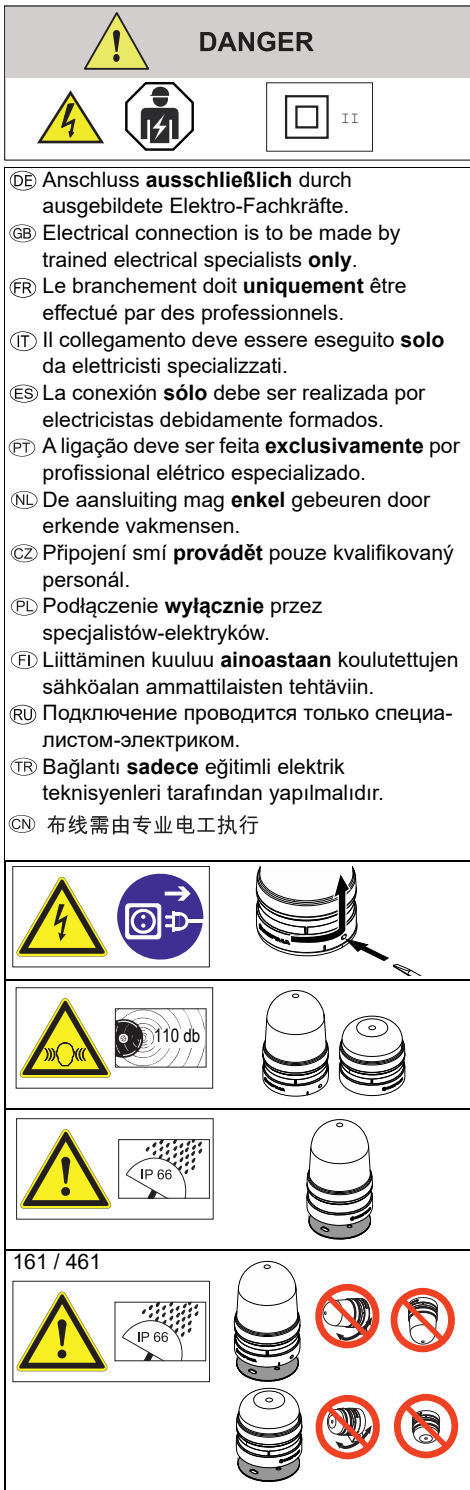

TwinLIGHT	261 x10 70 261 x10 60	12V/24V≈ 115V/60Hz - 230V/50Hz	<175 mA < 65 mA
TwinFLASH	261 x20 70 261 x20 60	12V/24V≈ 115V/60Hz - 230V/50Hz	<150 mA <100 mA
TriColour 	261 430 70 261 430 60	12V/24V≈ 115V/60Hz- 230V/50Hz	<135 mA < 50 mA
LED Rotating	261 x40 70 261 x40 60	12V/24V≈ 115V/60Hz- 230V/50Hz	<120 mA <100 mA
TwinLIGHT 	461 x10 70 461 x10 60	12V/24V≈ 115V/60Hz - 230V/50Hz	<290 mA <150 mA
TwinFLASH 	461 x20 70 461 x20 60	12V/24V≈ 115V/60Hz - 230V/50Hz	<290 mA <205 mA
	161 700 70 161 700 60	12V/24V≈ 115V/60Hz - 230V/50Hz	<135 mA <105 mA

1

1a- 261 700 01
1b- 261 700 02
1c- 261 700 06
1d- 261 700 07
1e- 261 700 03
1f- 261 700 05



1a



IP66

4x










Ø5,2 mm
Ø0,20"

85 mm 3.35"
55 mm 2.17"
11 mm
5,5 mm 0.22"
16,5 mm 0.65"
36 mm
1,42"
0,44"

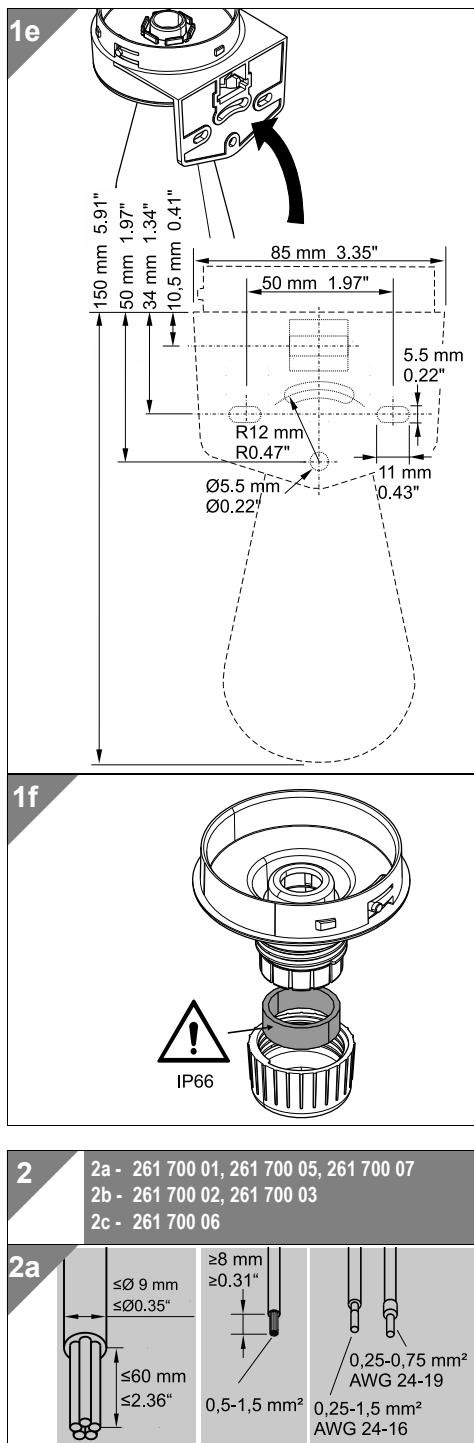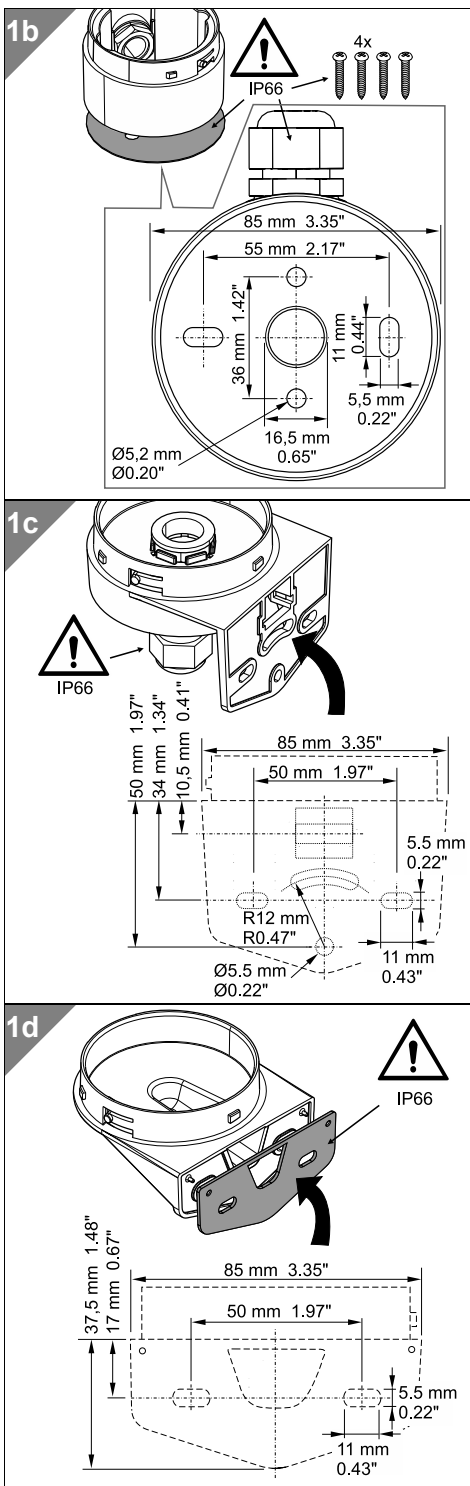


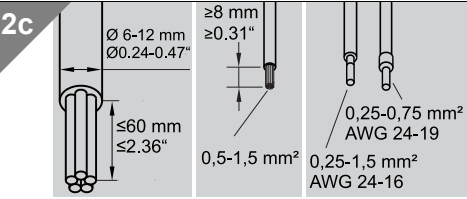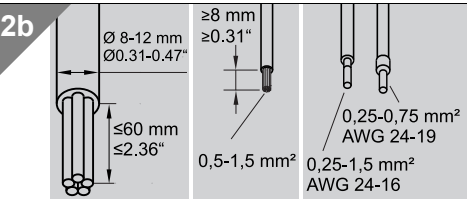


- 3**
- 3a - 261 700 01
 - 3b - 261 700 02
 - 3c - 261 700 06
 - 3d - 261 700 07
 - 3e - 261 700 03
 - 3f - 261 700 05

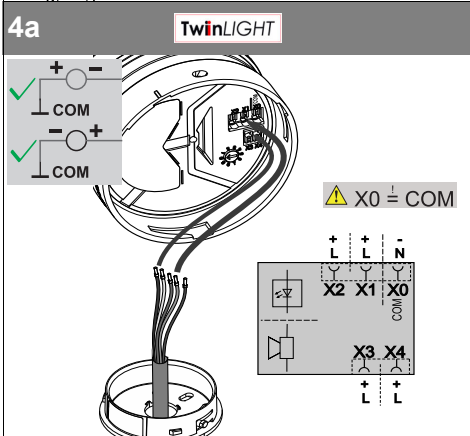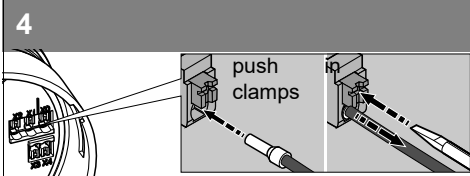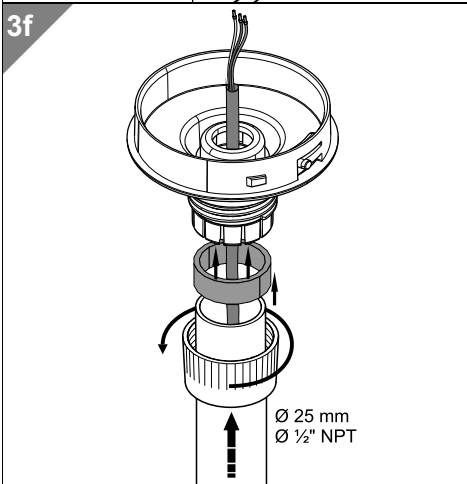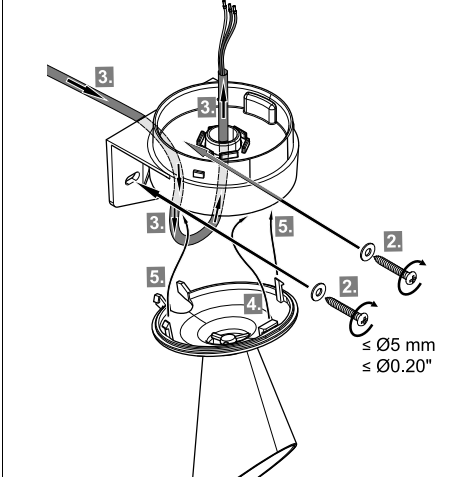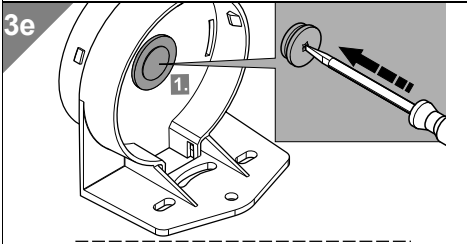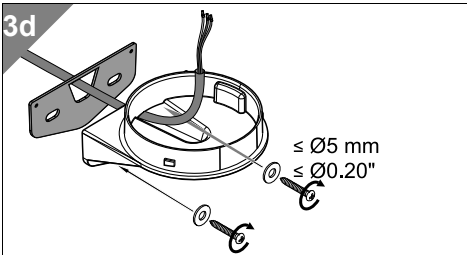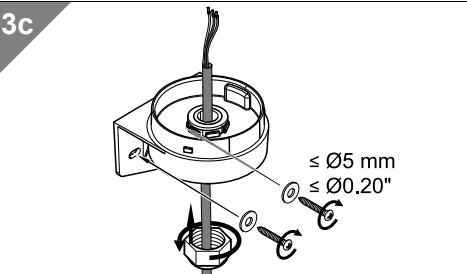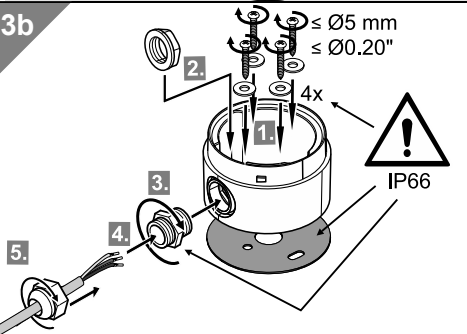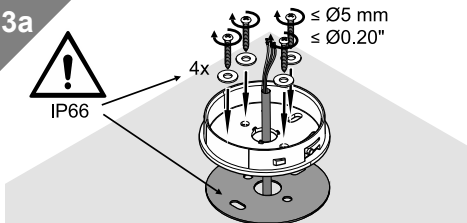


LED	X2	X1	X0 (COM)	Function
				permanent
				blinking
TONE	X3	X4	X0 (COM)	Function

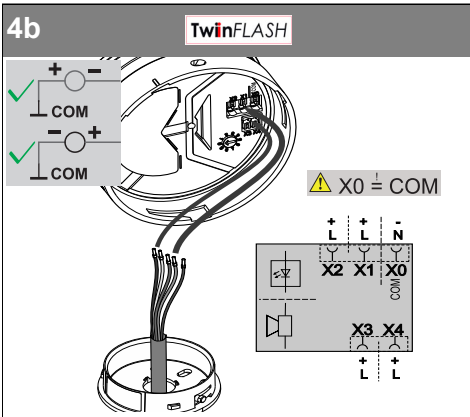


LED	X2	X1	X0 (COM)	Function
				flashing
				EVS
TONE	X3	X4	X0 (COM)	Function

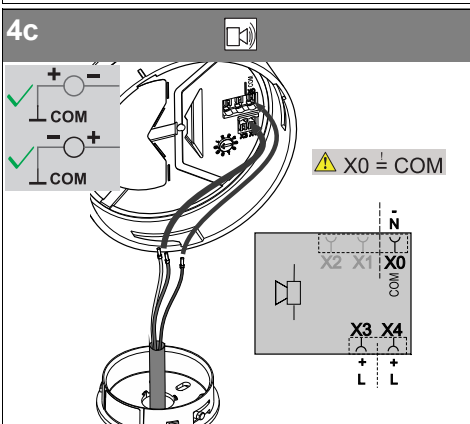

TONE	X3	X4	X0 (COM)	Function

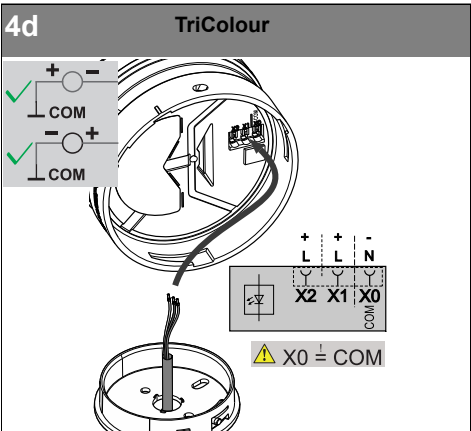

LED	X2	X1	X0 (COM)	Function
				GN
				RD
				YE

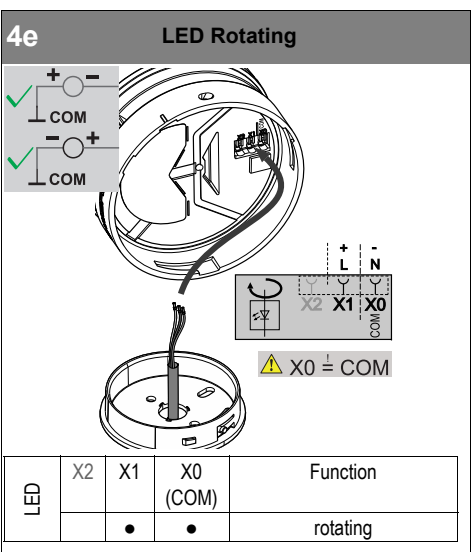

LED	X2	X1	X0 (COM)	Function
				rotating

5

NOTICE

dB = dB A (SPL) 1m

Tone		[dB]	[dB]
0	110 Hz	107	99
1	3.3 kHz	106	101
2	1Hz	110	101
3	20Hz	110	101
4	1Hz	95	94
5	7Hz	99	92
6	1Hz	101	93
7	1Hz	100	92
8	0.5 Hz	110	101
9	700 Hz	97	92

