
 
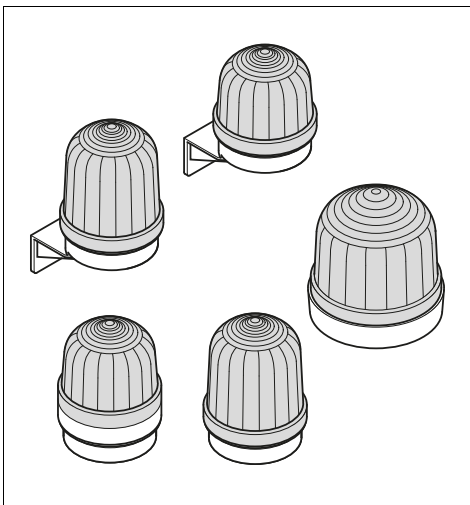




- (D) Anschluss **ausschließlich** durch ausgebildete Elektro-Fachkräfte.
- (GB) Electrical connection is to be made by trained electrical specialists **only**.
- (F) Le branchement doit **uniquement** être effectué par des professionnels.
- (I) Il collegamento deve essere eseguito **solo** da elettricisti specializzati.
- (E) La conexión **sólo** debe ser realizada por electricistas debidamente formados.
- (PT) A ligação deve ser feita **exclusivamente** por profissional elétrico especializado.
- (NL) De aansluiting mag **enkel** gebeuren door erkende vakmensen.
- (CZ) Připojení smí **provádět** pouze kvalifikovaný personál.
- (PL) Podłączenie **wyłącznie** przez specjalistów-elektryków.
- (FI) Liittäminen kuuluu **ainoastaan** koulutettujen sähköalan ammattilaisten tehtäviin.
- (RUS) Подключение проводится только специа-листом-электриком.
- (TR) Bağlantı **sadece** eğitimli elektrik teknisyenleri tarafından yapılmalıdır.
- (CN) 布线需由专业电工执行

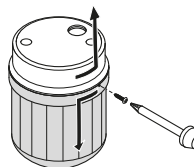

EN 60947-5-1

2x1 x00 67	115 V~, 25 mA, I ₀ < 500 mA
2x1 x00 68	230 V~, 25 mA, I ₀ < 500 mA
2x1 x00 75	24 V~, 45 mA, I ₀ < 500 mA
2x4 x00 67	115 V~, 25 mA, I ₀ < 500 mA
2x4 x00 68	230 V~, 25 mA, I ₀ < 500 mA
2x4 x00 75	24 V~, 45 mA, I ₀ < 500 mA
2x2 x00 55	24 V~, 100 mA, ~ 0.75 Hz
2x2 x00 67	115 V~, 50/60 Hz, 20 mA, ~ 0.75 Hz
2x2 x00 68	230 V~, 50/60 Hz, 30 mA, ~ 0.75 Hz
2x5 x00 55	24 V~, 100 mA, ~ 0.75 Hz
2x5 x00 67	115 V~, 50/60 Hz, 20 mA, ~ 0.75 Hz
2x5 x00 68	230 V~, 50/60 Hz, 30 mA, ~ 0.75 Hz


EN 60598-2-1

200 x00 00	12 – 240 V~, ≤ 7 W
203 x00 00	12 – 240 V~, ≤ 7 W
203 x01 00	12 – 240 V~, ≤ 5 W
210 x00 00	12 – 240 V~, ≤ 10 W
213 x00 00	12 – 240 V~, ≤ 10 W
220 x00 00	12 – 240 V~, ≤ 10 W
223 x00 00	12 – 240 V~, ≤ 10 W




BA 15 d

956 x00 75	24 V~, < 45 mA
956 x00 67	115 V~, < 15 mA
956 x00 68	230 V~, < 15 mA

 


BA 15 d, < 42 mm (1.65"), 5W, (20x)

955 840 34	12 V
955 840 35	24 V
955 840 32	30 V
955 840 57	115 V
955 840 38	230 V

 

BA 15 d, < 52 mm (2.05"), 7W, (21x / 22x)


955 015 34	12 V
955 015 35	24 V
955 015 36	48 V
955 015 57	115 V
955 015 38	230 V

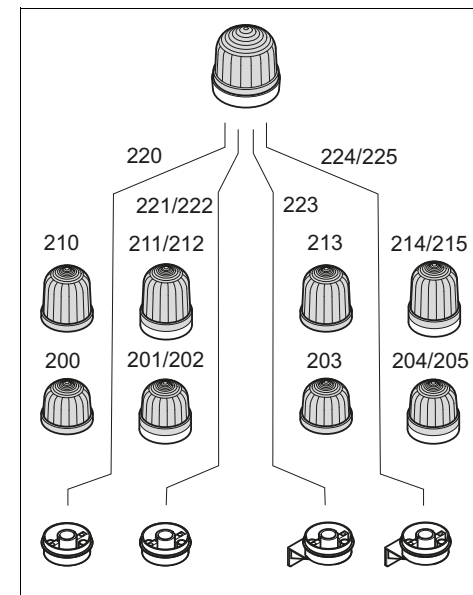


1








1a - 20x, 21x
1b - 22x

1a

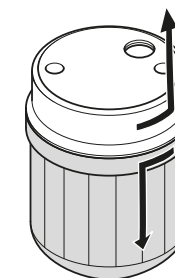

1b

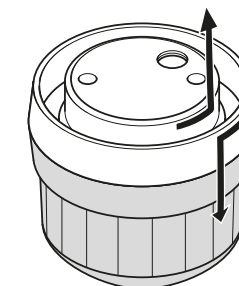

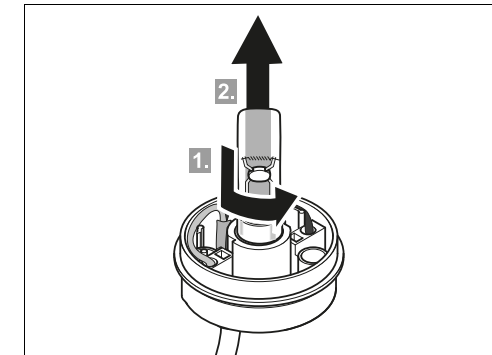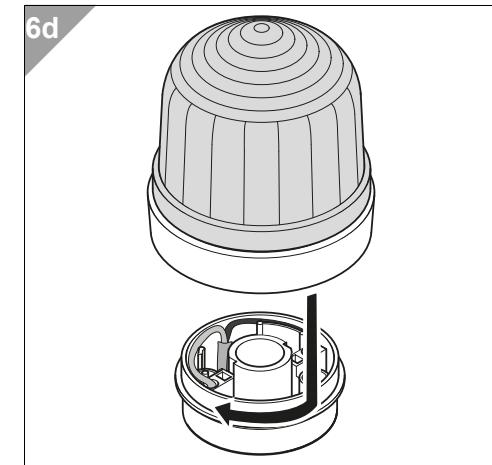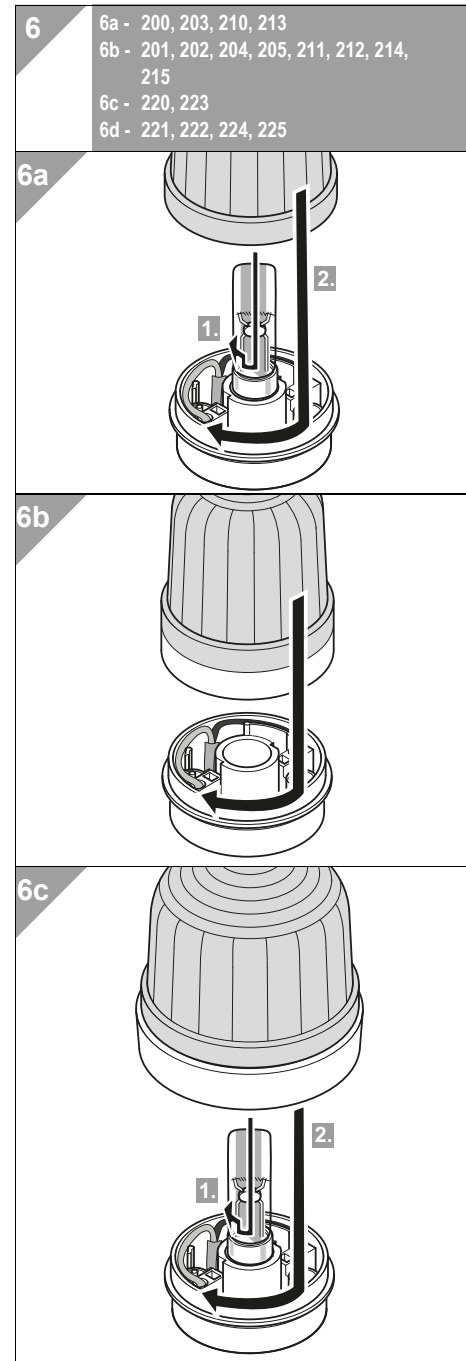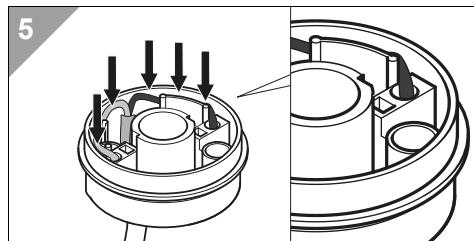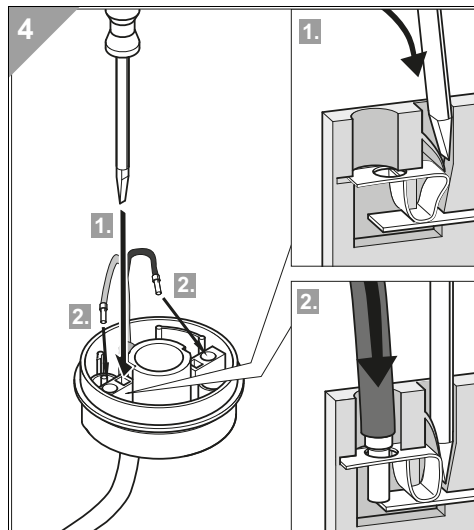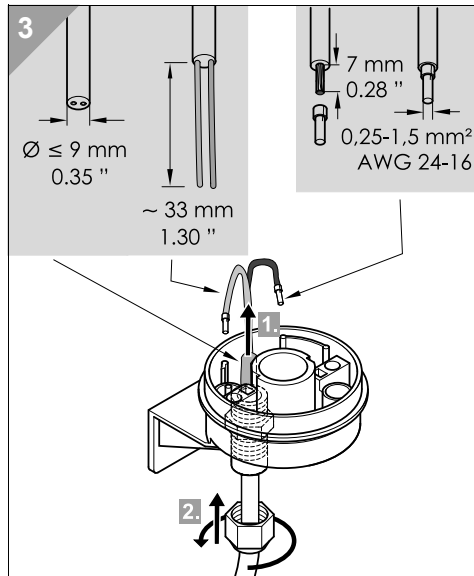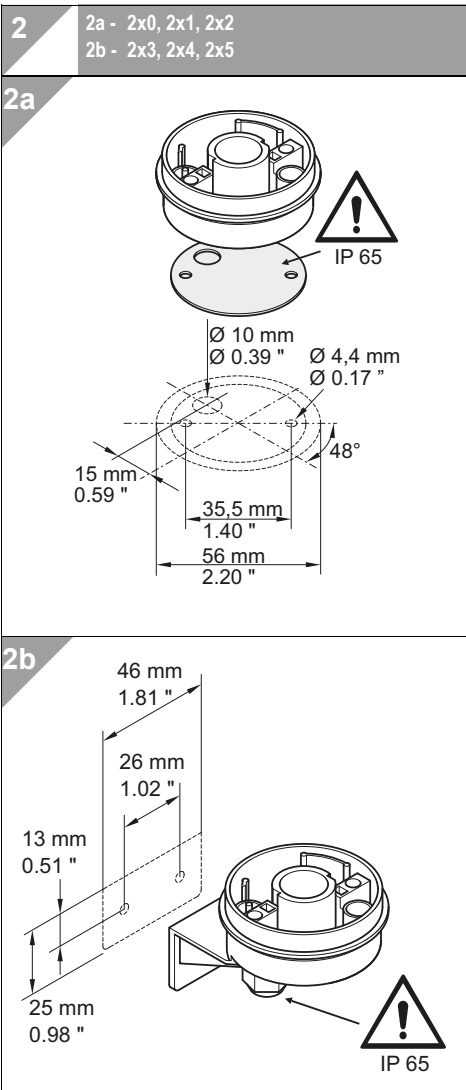

931020000101_AB
310.200.001

WERMA[®]