


Prowadnica kulkowa H27
Ball bearing slide H27
Шариковая направляющая H27
Направляюча кулькова H27



	 L mm	 AV mm		 kg		
PK-0H27-3000	300	109	niepełny partial неполное неповний	15	ocynk galvanized гальваника оцинкований	stal steel сталь сталь
PK-0H27-3500	350	124				
PK-0H27-4000	400	134				
PK-0H27-4500	450	149				
PK-0H27-5000	500	184				

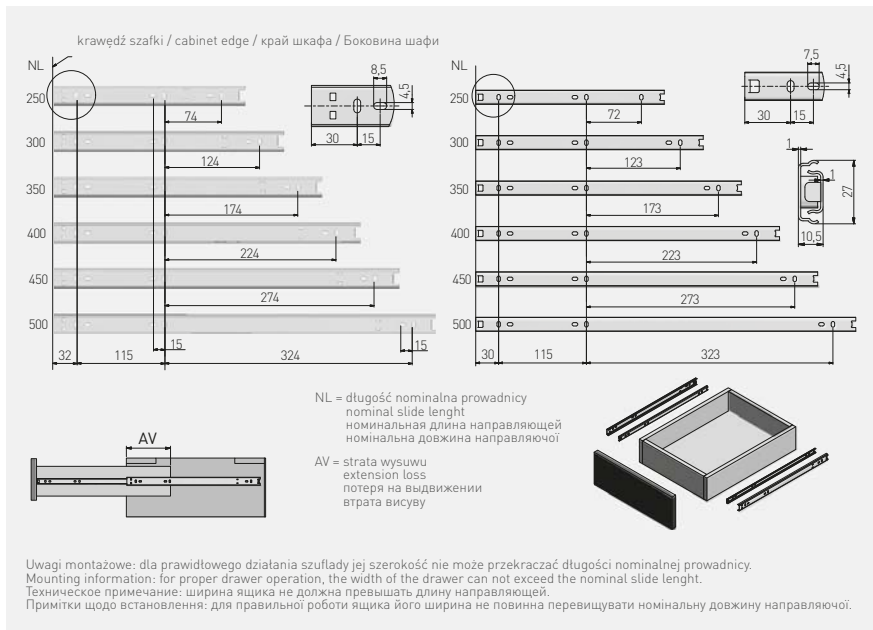

FRIENDLY