


Uchwył HEXA
Handle HEXA
Ручка HEXA
Ручка HEXA

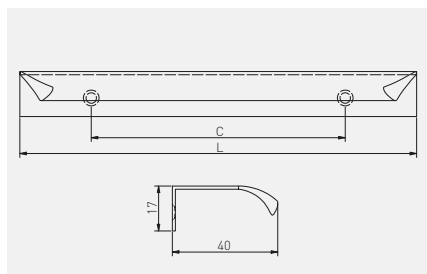

C mm	L mm				
		chrom, chrome, хром, хром	aluminium, aluminium, алюминий, алюминий	biały mat, white matt, белый матовый, білий матовий	
32	50	UA-HEXA-32-01	UA-HEXA-32-05	UA-HEXA-32-10M	aluminium, aluminium, алюминий, алюминий
96	150	UA-HEXA-96-01	UA-HEXA-96-05	UA-HEXA-96-10M	
160	193	UA-HEXA-160-01	UA-HEXA-160-05	UA-HEXA-160-10M	
192	225	UA-HEXA-192-01	UA-HEXA-192-05	UA-HEXA-192-10M	
256	266	UA-HEXA-256-01	UA-HEXA-256-05	UA-HEXA-256-10M	
320	353	UA-HEXA-320-01	UA-HEXA-320-05	UA-HEXA-320-10M	

C mm	L mm				
		złoty szczerkowany, brushed gold, матовое золото, золото шліфоване	czarny mat, black matt, чёрный матовый, чорний матовий	jasne złoto szczerkowane, bright brushed gold, светлое шліфованное золото, світле шліфоване золото	
32	50	UA-HEXA-32-18	UA-HEXA-32-20M	UA-HEXA-32-22	aluminium, aluminium, алюминий, алюминий
96	150	UA-HEXA-96-18	UA-HEXA-96-20M	UA-HEXA-96-22	
160	193	-	UA-HEXA-160-20M	UA-HEXA-160-22	
192	225	UA-HEXA-192-18	UA-HEXA-192-20M	UA-HEXA-192-22	
256	266	-	UA-HEXA-256-20M	UA-HEXA-256-22	
320	353	-	UA-HEXA-320-20M	UA-HEXA-320-22	