


Uchwyt HEXI
Handle HEXI
Ручка HEXI
Ручка HEXI

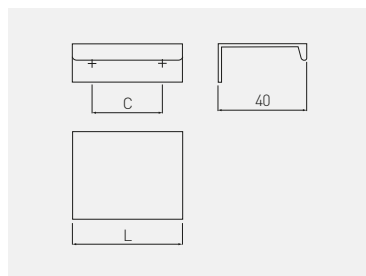

 C mm	 L mm				
		chrom, chrome, хром, хром	aluminium, aluminium, алюминий, алюминий	biały mat, white matt, белый матовый, белый матовый	czarny mat, black matt, чёрный матовый, чёрный матовый
32	50	UA-HEXI-01	UA-HEXI-05	UA-HEXI-10M	UA-HEXI-20M
96	150	UA-HEXI96-01	UA-HEXI96-05	UA-HEXI96-10M	UA-HEXI96-20M
128	150	UA-HEXI-128-01	UA-HEXI-128-05	UA-HEXI-128-10M	UA-HEXI-128-20M
160	190	UA-HEXI-160-01	UA-HEXI-160-05	UA-HEXI-160-10M	UA-HEXI-160-20M
192	225	UA-HEXI192-01	UA-HEXI192-05	UA-HEXI192-10M	UA-HEXI192-20M
256	290	UA-HEXI-256-01	UA-HEXI-256-05	UA-HEXI-256-10M	UA-HEXI-256-20M
320	360	UA-HEXI-320-01	UA-HEXI-320-05	UA-HEXI-320-10M	UA-HEXI-320-20M
do cięcia to cut для резки	3500	-	UA-HEXI-3500-05	-	UA-HEXI-3500-20M

aluminium,
aluminium,
алюминий,
алюминий

 C mm	 L mm			
		antracyt, anthracite, антрацит, антрацит	złoty szczotkowany, brushed gold, матовое золото, золото шлифованное	
32	50	UA-HEXI-60	UA-HEXI-18	aluminium, aluminium, алюминий, алюминий
96	150	UA-HEXI96-60	UA-HEXI96-18	
160	190	UA-HEXI-160-60	UA-HEXI-160-18	
192	225	UA-HEXI192-60	UA-HEXI192-18	
256	290	UA-HEXI-290-60	UA-HEXI-290-18	
320	360	UA-HEXI-360-60	UA-HEXI-360-18	