
 
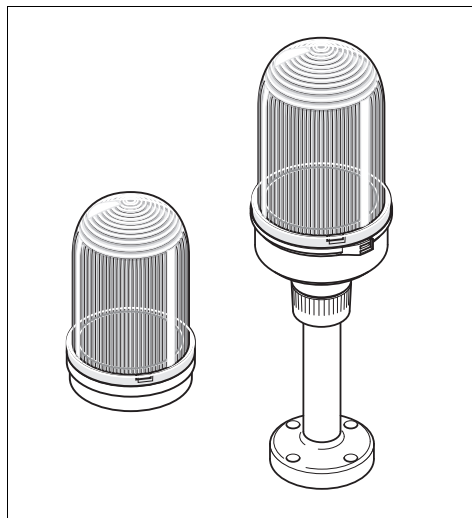

 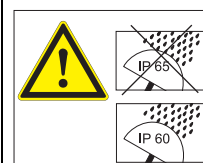


826, 827: EN 60598



828: EN 60947-5-1

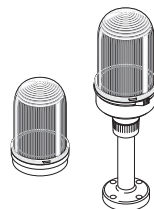


- DE** Anschluss **ausschließlich** durch ausgebildete Elektro-Fachkräfte.
- GB** Electrical connection is to be made by trained electrical specialists **only**.
- FR** Le branchement doit **uniquement** être effectué par des professionnels.
- IT** Il collegamento deve essere eseguito **solo** da elettricisti specializzati.
- ES** La conexión **sólo** debe ser realizada por electricistas debidamente formados.
- PT** A ligação deve ser feita **exclusivamente** por profissional eléctrico especializado.
- NL** De aansluiting mag **enkel** gebeuren door erkende vakmensen.
- CZ** Připojení smí **provádět** pouze kvalifikovaný personál.
- PL** Podłączenie **wyłącznie** przez specjalistów-elektryków.
- FI** Liittäminen kuuluu **ainoastaan** koulutettujen sähköalan ammattilaisten tehtäviin.
- RU** Подключение проводится только специа-листом-электриком.
- TR** Bağlantı **sadece** eğitimli elektrik teknisyenleri tarafından yapılmalıdır.
- CN** 布线需由专业电工执行
















826 xx0 00	12 – 240 V~, B 15 d, ≤ 15 W
827 xx0 75	24 V~, ≤ 15 W
827 xx0 77	115 V~, ≤ 15 W
827 xx0 78	230 V~, ≤ 15 W
828 xx0 54	12 V~, 500 mA
828 xx0 55	24 V~, 300 mA
828 xx0 67	115 V~, 65 mA
828 xx0 68	230 V~, 150 mA
828 x80 70	10 – 60 V~, ≤ 500 mA
828 x20 55	24 V~, 500 mA, (0,5 Hz/1,5 Hz)
	12 – 24 V~
828 x30 55	3,5 - 6,5 W, ≤ 290 mA
	BA 15 d
955 826 35	24 V, 15 W
955 826 37	115 V, 15 W
955 826 38	230 V, 15 W

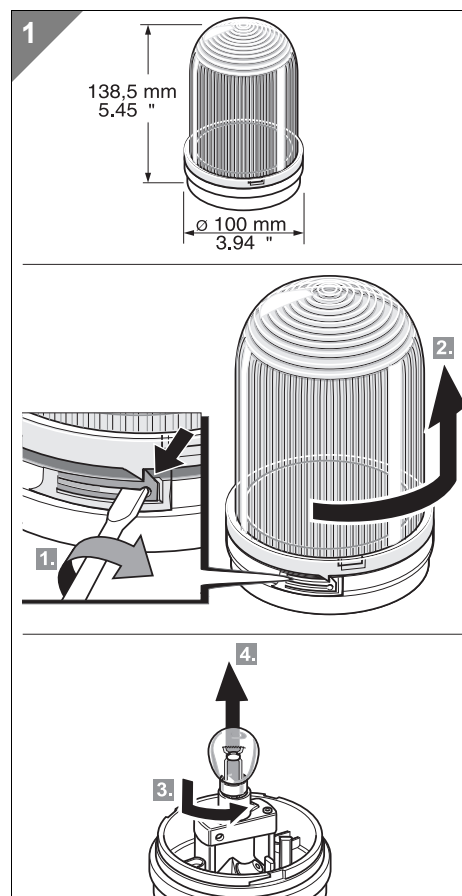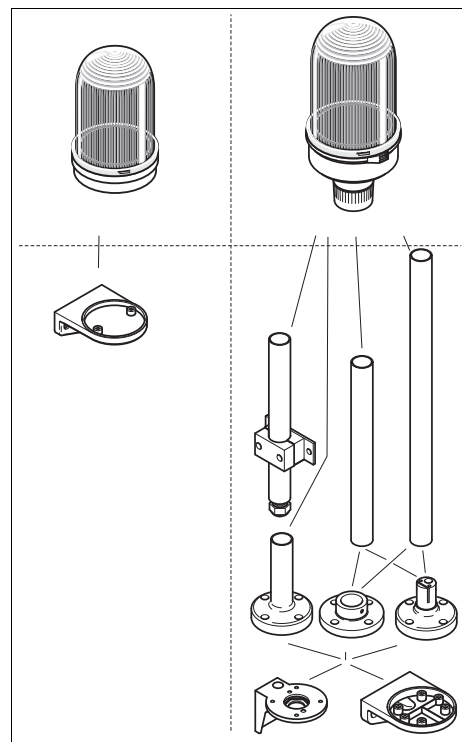

- 2**
- 2a - 826, 827, 828
- 2b - 826, 827, 828 + 975 826 05
- 2c - 826 x10 00, 827 x10 xx, 828 x40 xx + 975 845 10, 975 840 90

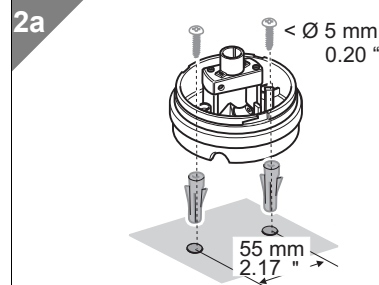

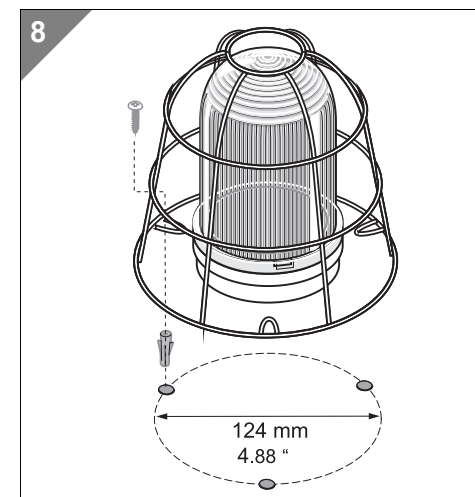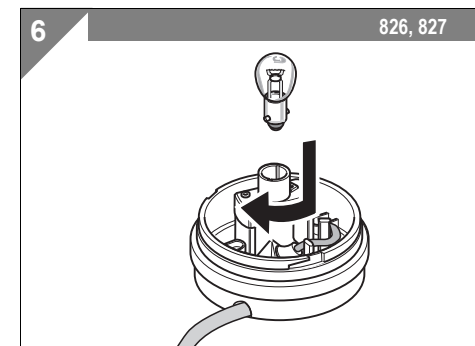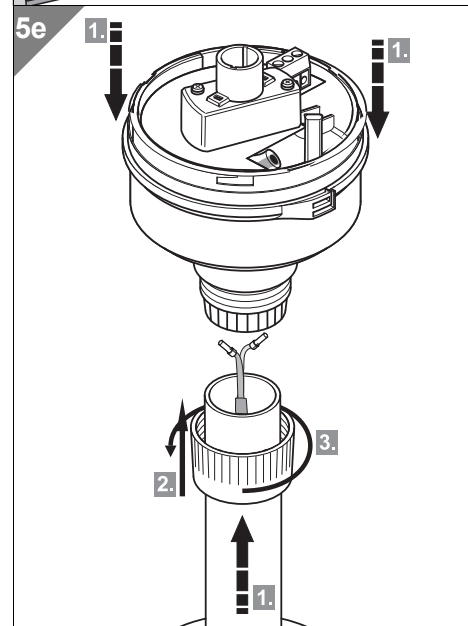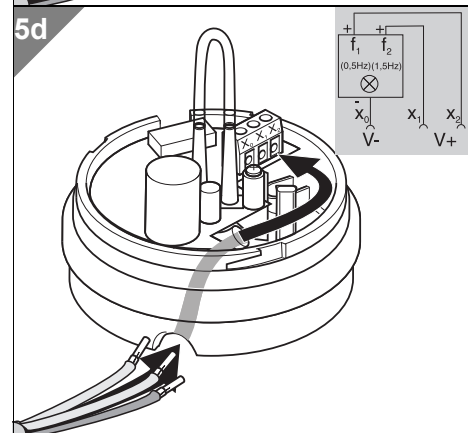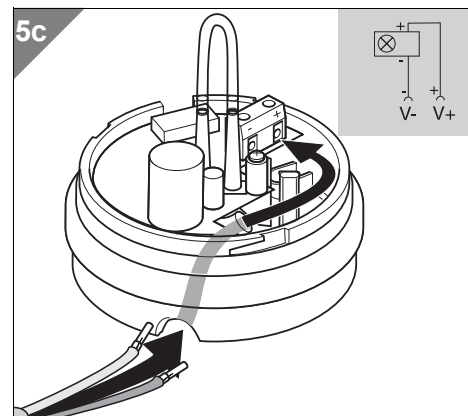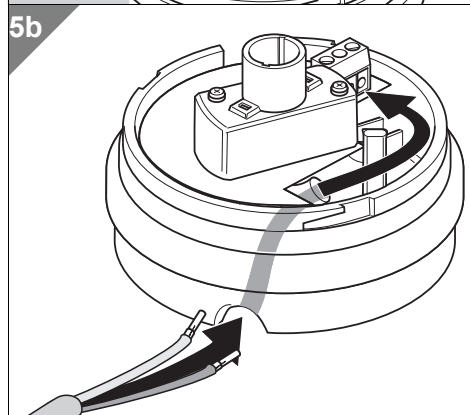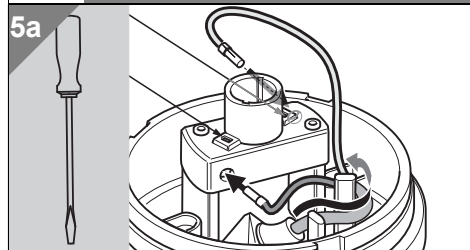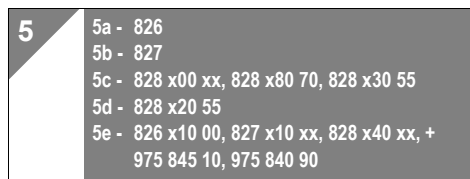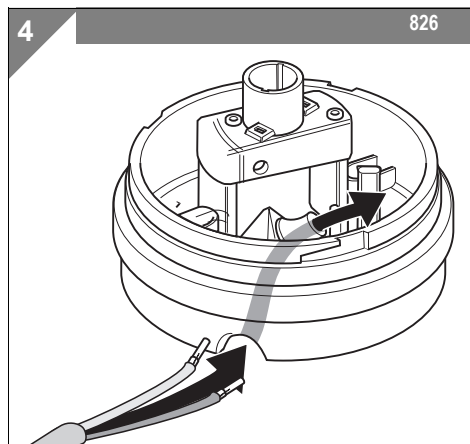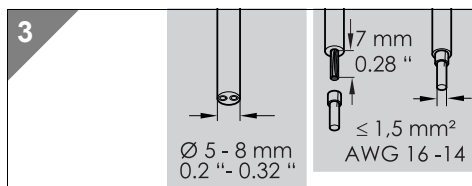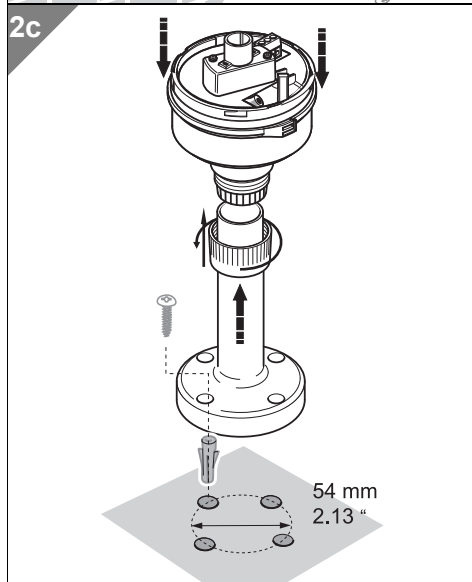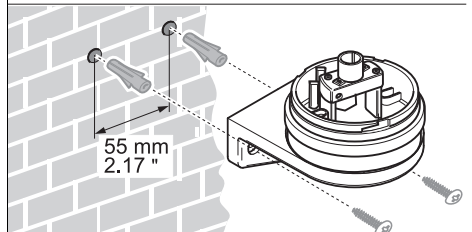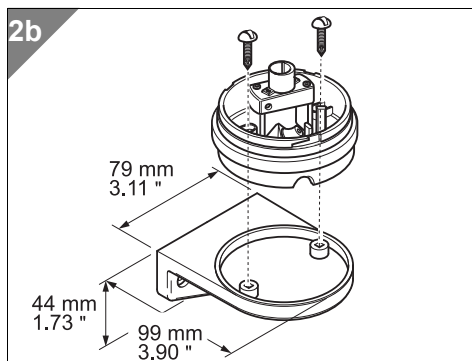

931082600101_AI
310.826.001

WERMA