

SMD 4040 RGB LED Strip

120 LED/M DC24V



Product Description :

This is a PWM control RGB color LED strip without pixel
 120pcs SMD RGB LED per meter, 5meters/ reel,
 8mm PCB width

The cutting unit length is 100mm (24V)per section
 All soldering Pads are very large, allowing you to
 easily cut and reconnect

DC24V constant voltage operation

Both ends have 4pin bare wires for powering


3M tape attached on backside of FPC

Waterproof types IP64, IP65

Product Datasheet

Product Number	S008120TC3PZ	Luminance/M	R:254 G:626 B:143lm
Operating Voltage	DC24V	Ra	/
Power/M	27W	Beam Angle	120°
SMD Type	SMD 4040	Size (mm)	5000 * 8mm
LED Qty/M	120	IP Rate	IP20/IP64/IP65
Color	RGB	Operation Temperature	- 25 ~ 60 °C
Pixel/M	/	Material	FPC
Control	PWM	Cutting Length	50mm
Wavelength	R:620-625 G:520-525 B:460-465nm	Net Weight/Roll	0.24KG


Outline Dimension (unit: mm)

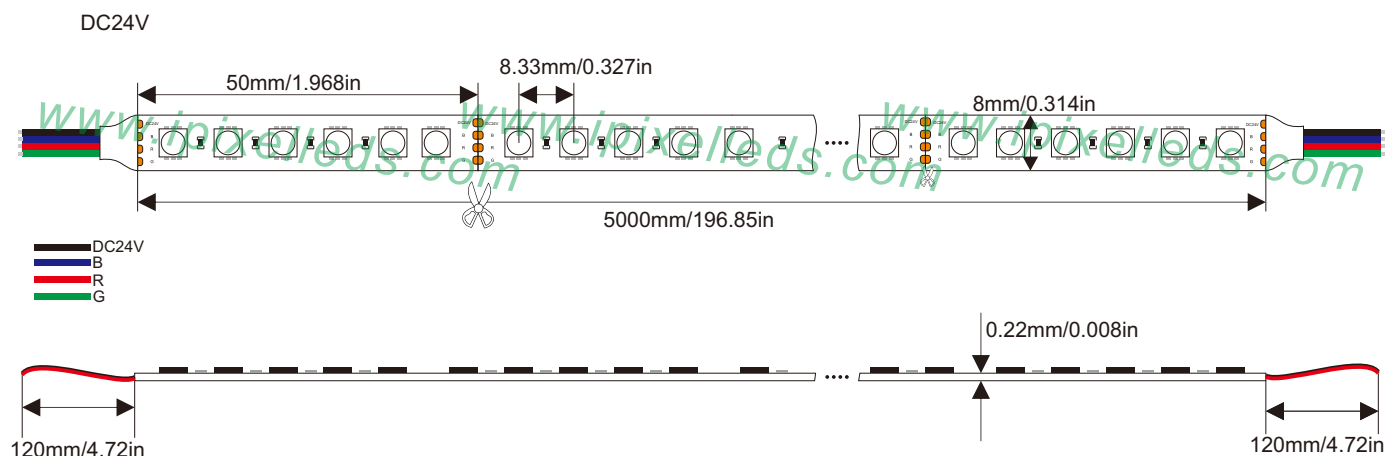

◆ Order number

DC24V	RGB	White PCB	IP20	S008120TC3PZ/C1
DC24V	RGB	White PCB	IP64	S008120TC3PZ/C2
DC24V	RGB	White PCB	IP65	S008120TC3PZ/C3

◆ Wiring diagram

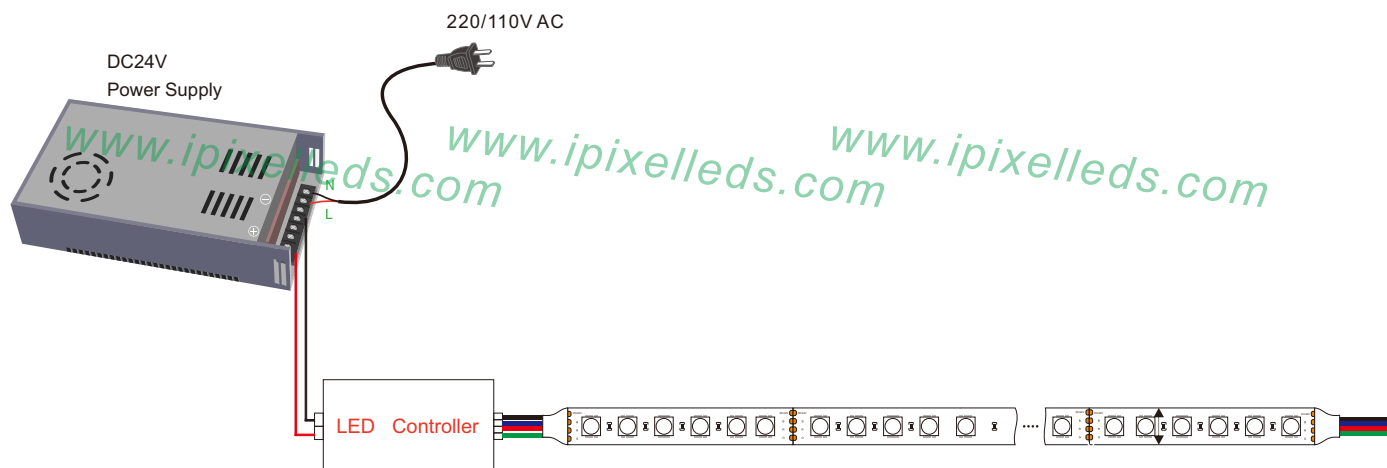

◆ Strip IP Rate



◆ Accessories



Screw




Silicone clip



End cap

◆ Schematic diagram of maximum bending prevention

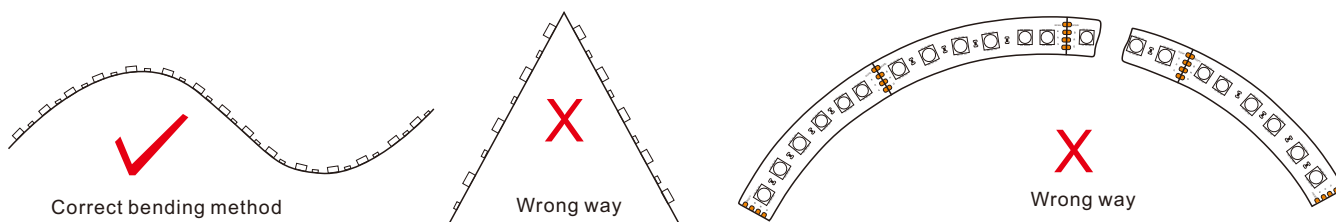

Note: The parameters are subject to change without notice!