

DC24V SMD5050 RGB LED Strip 60LEDs/m

◆ Product Description :

This is a PWM control RGB color LED strip without Pixel
 60pcs SMD RGB 5050 LEDs per meter
 5meters/reel, 10mm PCB width
 The cutting unit length is 100mm per section
 The PCB is made by 2 Ounce thick copper
 All soldering Pads are very large, allowing you to
 easily cut and reconnect
 DC24V constant voltage operation
 Both ends have 4pin bare wires for powering
 3M tape attached on backside of FPC
 3 different waterproof types IP64, IP65, IP67




◆ Product Datasheet

Product Number	S010060CC3PZ	Luminance/M	R:89 G:239 B:61lm
Operating Voltage	DC24V	Ra	/
Power/M	14.4W	Beam Angle	120°
SMD Type	SMD 5050	Size (mm)	5000 * 10mm
LED Qty/M	60	IP Rate	IP20/IP64/IP65/IP67
Color	RGB	Operation Temperature	- 25 ~ 60 °C
Pixel/M	/	Material	FPC
Control	PWM	Cutting Length	100mm
Wavelength	R:620-625 G:520-525 B:460-465NM	Net Weight/Roll	0.24KG

◆ Outline Dimension (unit: mm)


DC24V

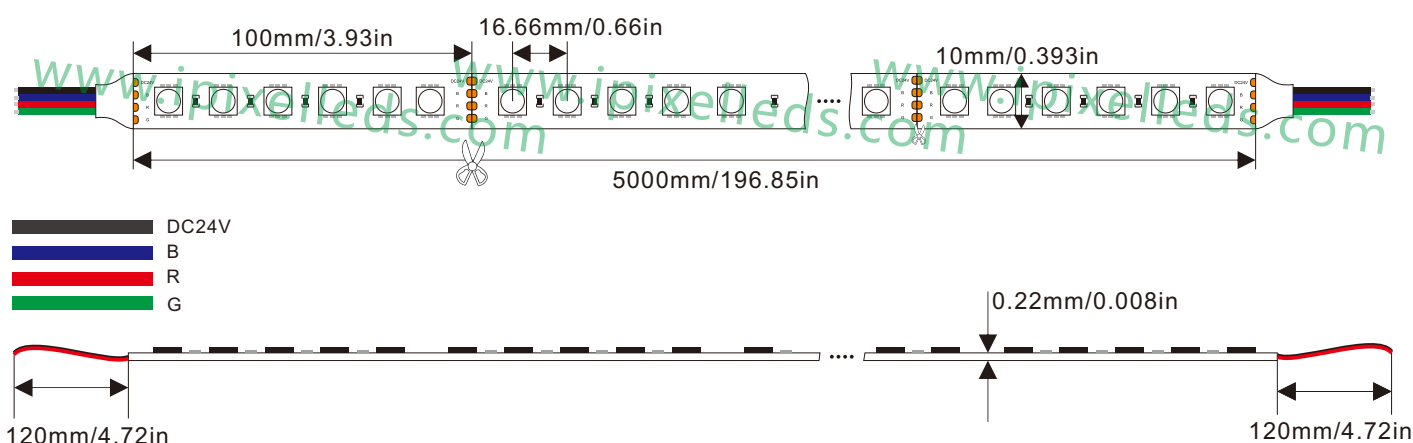


Order number

DC24V	RGB	White PCB	IP20	S010060CC3PZ/C1
DC24V	RGB	White PCB	IP64	S010060CC3PZ/C2
DC24V	RGB	White PCB	IP65	S010060CC3PZ/C3
DC24V	RGB	White PCB	IP67	S010060CC3PZ/C4

Wiring diagram

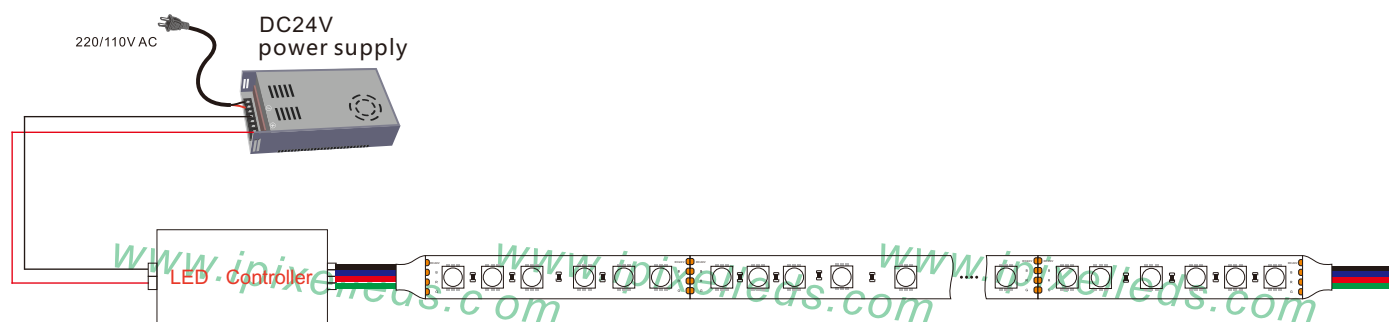

Strip IP Rate

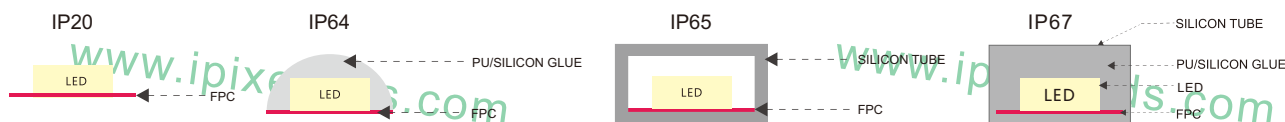

Accessories



Screw




Silicone clip



End cap

Schematic diagram of maximum bending prevention

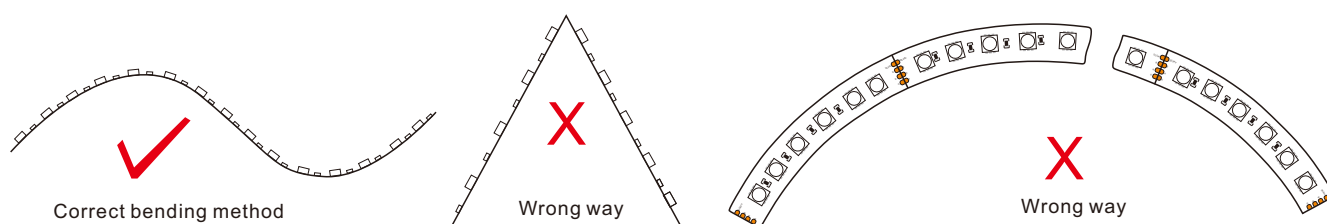

Note: The parameters are subject to change without notice!