


Auto Address DMX512 RGB LED Strip 60LEDs/M

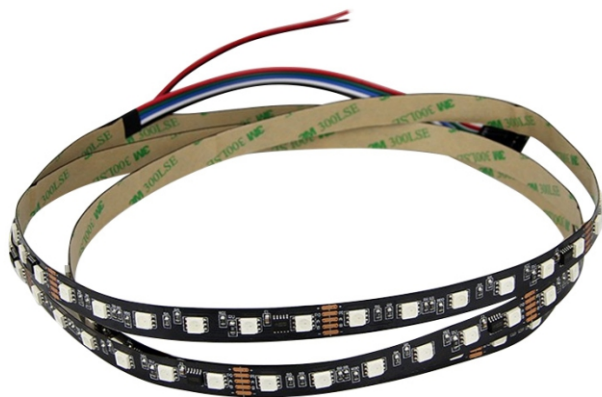

Product Description :

Compare to the manual address DMX strip, this is much more easier to use, you don't need a address coder

60LEDs & 30 DMX channels per meter (10Pixels)

The whole strip is 5meters long, but the cutting unit is 100mm, each section contains 6LEDs and 3 channels
300P 3M tape attached on backside of PCB

It's easy to run with any standard DMX512 controller




Product Datasheet

Product Number	S012060CC3DC6	Luminance/M	R: 320 G: 990 B: 170 lm
Operating Voltage	DC24V	Ra	/
Power/M	14.4W	Beam Angle	120°
SMD Type	SMD 5050	Size (mm)	5000 * 12mm
LED Qty/M	60	IP Rate	IP20/IP64/IP65/IP67
Color	RGB	Operation Temperature	- 25 ~ 60 °C
Pixel/M	10	Material	FPC
Control	Auto DMX512	Cutting Length	100mm
Wavelength	R:620-625 G:520-525 B:460-465nm	Net Weight/Roll	0.13KG

Outline Dimension (unit: mm)


DC24V

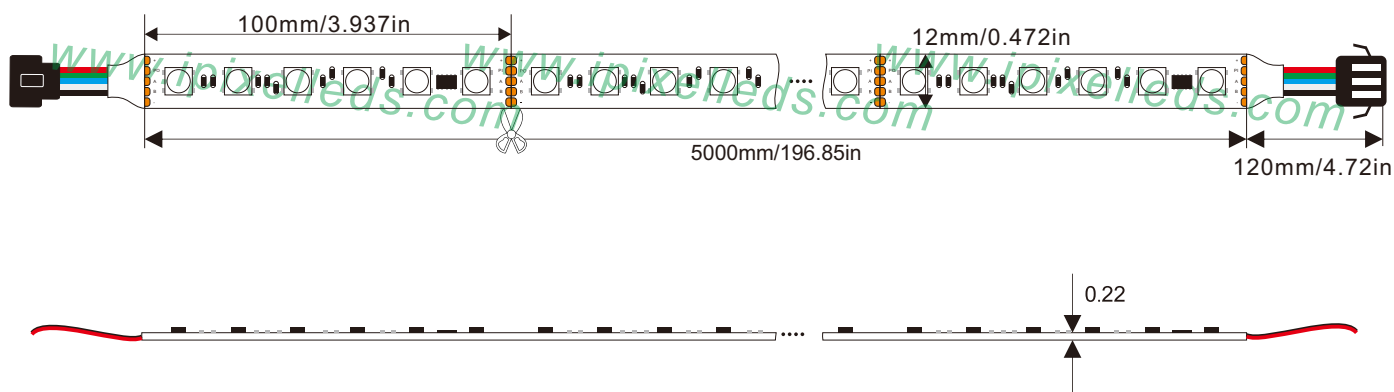


Order number

DC24V	RGB	White PCB	IP20	S012060CC3DC6/C1
DC24V	RGB	White PCB	IP64	S012060CC3DC6/C2
DC24V	RGB	White PCB	IP65	S012060CC3DC6/C3
DC24V	RGB	White PCB	IP67	S012060CC3DC6/C4
DC24V	RGB	Black PCB	IP20	S012060CC3DC6/C5
DC24V	RGB	Black PCB	IP64	S012060CC3DC6/C6
DC24V	RGB	Black PCB	IP65	S012060CC3DC6/C7
DC24V	RGB	Black PCB	IP67	S012060CC3DC6/C8

Wiring diagram

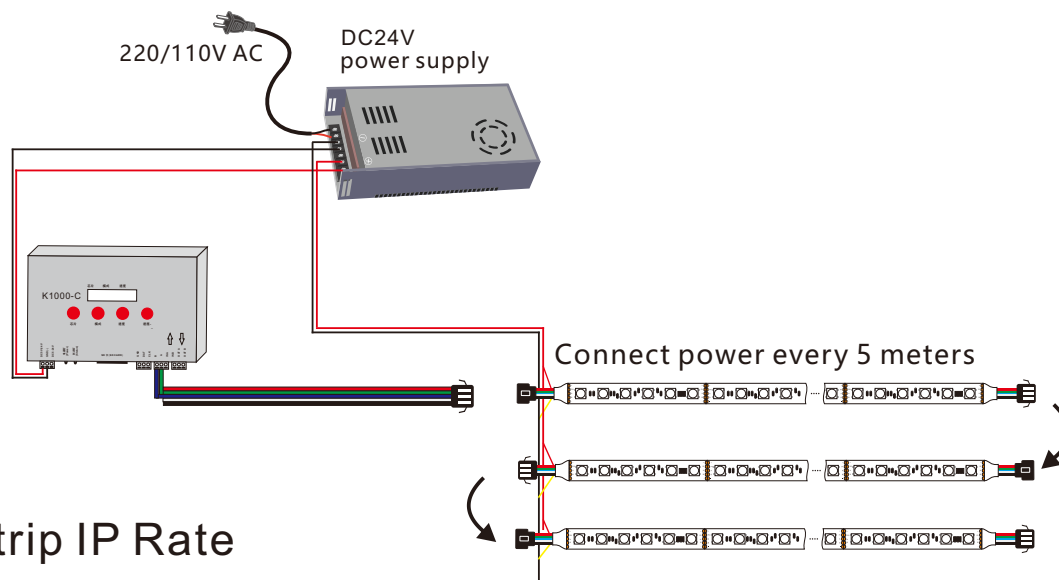

Strip IP Rate

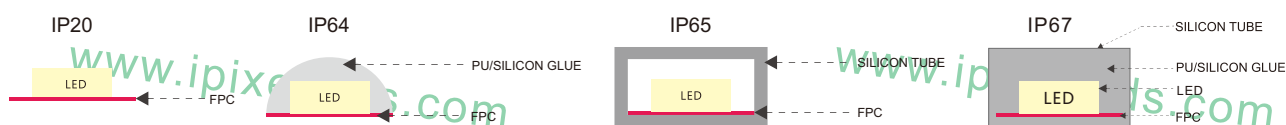

Accessories



Screw



Silicone clip



End cap

Note: The parameters are subject to change without notice!