


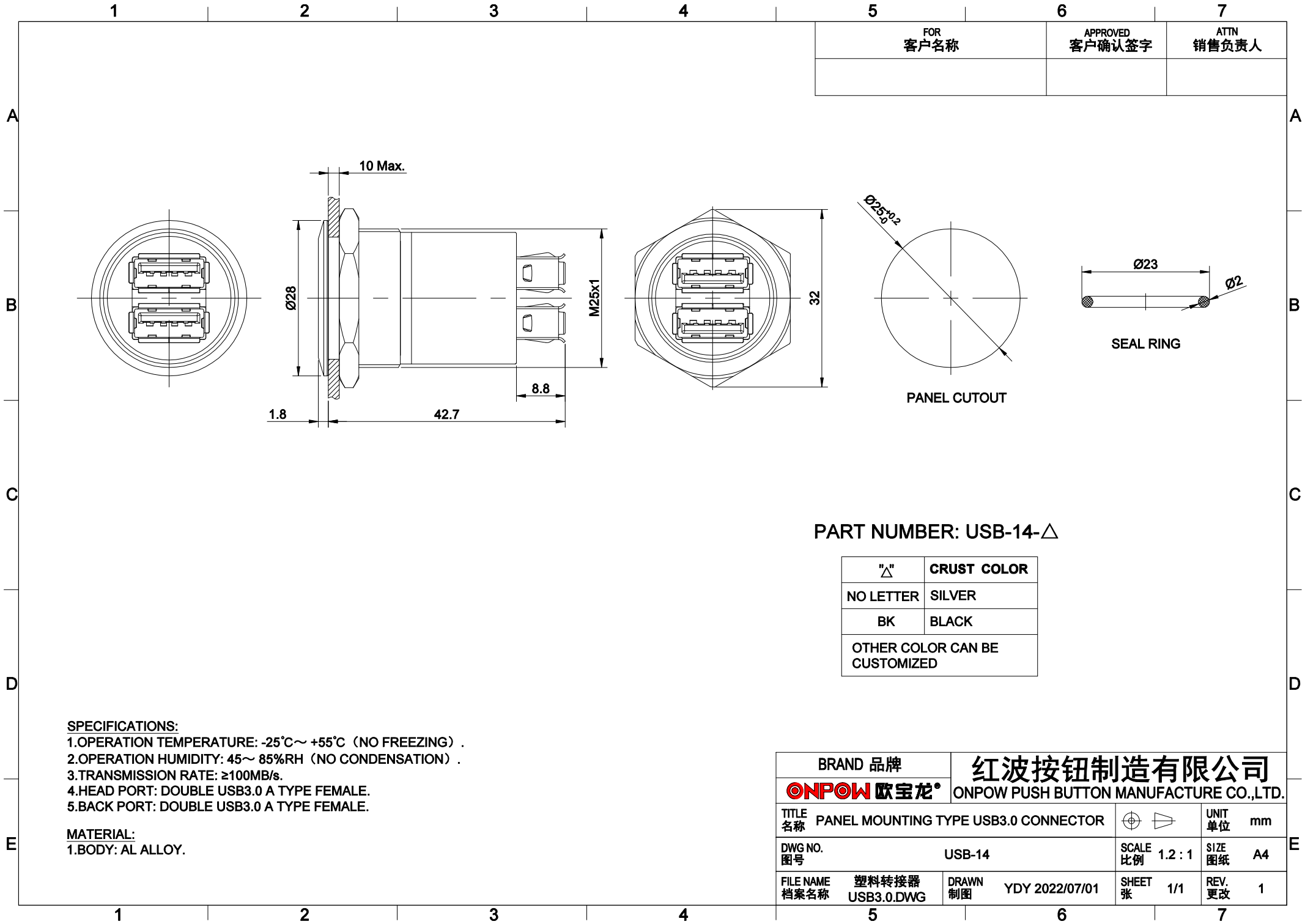

PART NUMBER: USB-14-△

| "△"                           | CRUST COLOR |
|-------------------------------|-------------|
| NO LETTER                     | SILVER      |
| BK                            | BLACK       |
| OTHER COLOR CAN BE CUSTOMIZED |             |

SPECIFICATIONS:

- 1.OPERATION TEMPERATURE: -25℃~ +55℃ (NO FREEZING) .
- 2.OPERATION HUMIDITY: 45~ 85%RH (NO CONDENSATION) .
- 3.TRANSMISSION RATE: ≥100MB/s.
- 4.HEAD PORT: DOUBLE USB3.0 A TYPE FEMALE.
- 5.BACK PORT: DOUBLE USB3.0 A TYPE FEMALE.

MATERIAL:

- 1.BODY: AL ALLOY.

| BRAND 品牌       |                                      | 红波按钮制造有限公司                             |                |          |         |
|----------------|--------------------------------------|----------------------------------------|----------------|----------|---------|
| ONPOW 欧宝龙®     |                                      | ONPOW PUSH BUTTON MANUFACTURE CO.,LTD. |                |          |         |
| TITLE 名称       | PANEL MOUNTING TYPE USB3.0 CONNECTOR |                                        |                | UNIT 单位  | mm      |
| DWG NO. 图号     | USB-14                               |                                        |                | SCALE 比例 | 1.2 : 1 |
| FILE NAME 档案名称 | 塑料转接器 USB3.0.DWG                     | DRAWN 制图                               | YDY 2022/07/01 | SHEET 张  | 1/1     |
|                |                                      |                                        |                | REV. 更改  | 1       |