


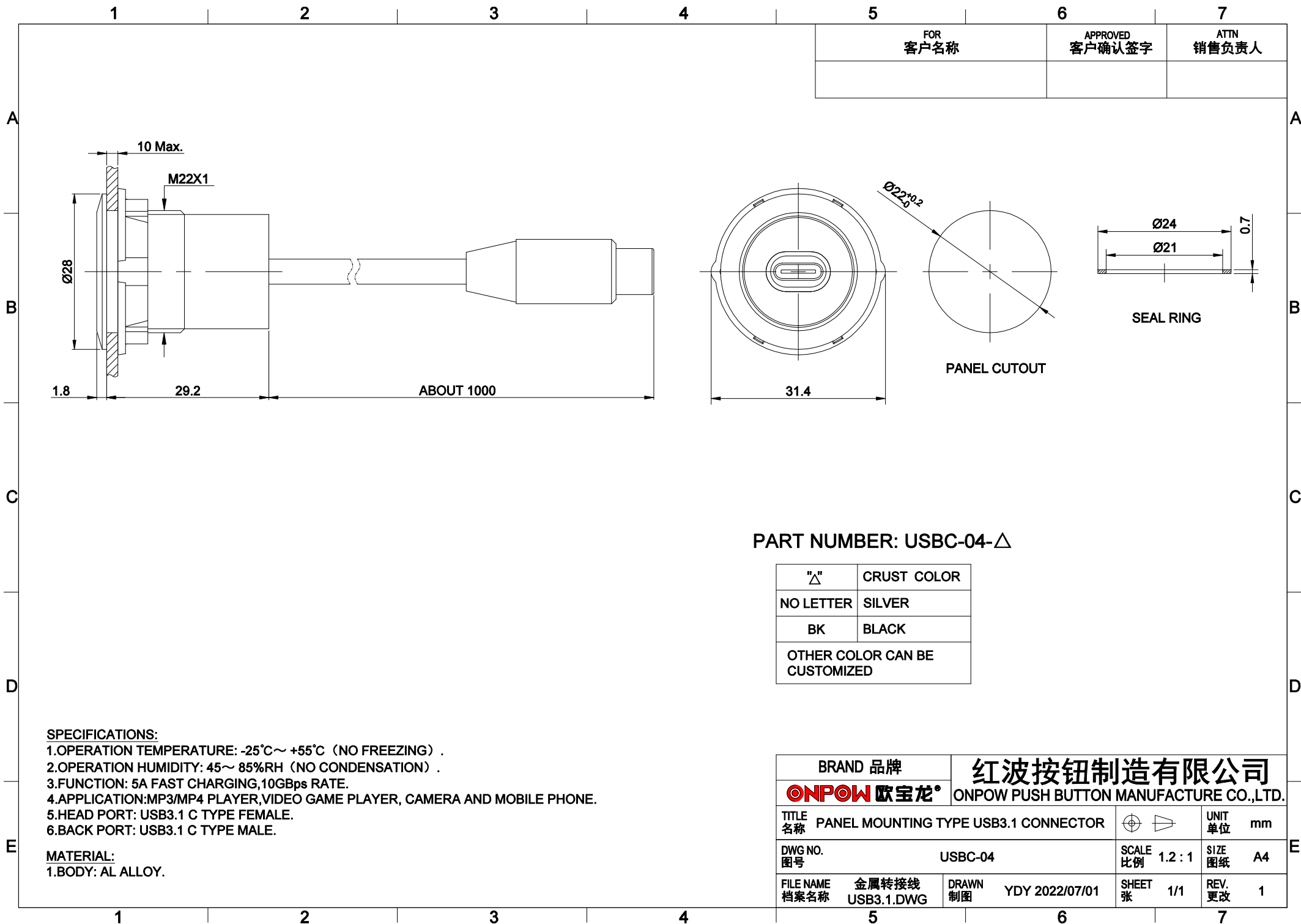

SPECIFICATIONS:

- 1.OPERATION TEMPERATURE: -25℃~ +55℃ (NO FREEZING) .
- 2.OPERATION HUMIDITY: 45~ 85%RH (NO CONDENSATION) .
- 3.FUNCTION: 5A FAST CHARGING,10GBps RATE.
- 4.APPLICATION:MP3/MP4 PLAYER,VIDEO GAME PLAYER, CAMERA AND MOBILE PHONE.
- 5.HEAD PORT: USB3.1 C TYPE FEMALE.
- 6.BACK PORT: USB3.1 C TYPE MALE.

MATERIAL:

- 1.BODY: AL ALLOY.

PART NUMBER: USBC-04-△

"△"	CRUST COLOR
NO LETTER	SILVER
BK	BLACK
OTHER COLOR CAN BE CUSTOMIZED	

BRAND 品牌		红波按钮制造有限公司			
ONPOW 欧宝龙®		ONPOW PUSH BUTTON MANUFACTURE CO.,LTD.			
TITLE 名称	PANEL MOUNTING TYPE USB3.1 CONNECTOR			UNIT 单位	mm
DWG NO. 图号	USBC-04	SCALE 比例	1.2 : 1	SIZE 图纸	A4
FILE NAME 档案名称	金属转接线 USB3.1.DWG	DRAWN 制图	YDY 2022/07/01	SHEET 张	1/1
		REV. 更改	1		