
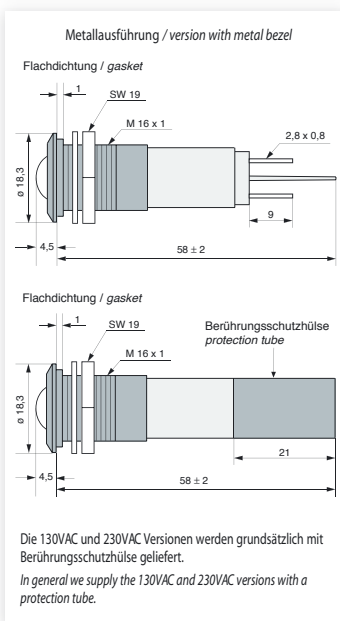


LED Signalleuchten LED Panel Mount Indicators

Standardreflektor runde Linse 130/230V AC mit Berührungsschutzhülse IP67 / Standard bezel round lens 130/230V AC with protection tube IP67

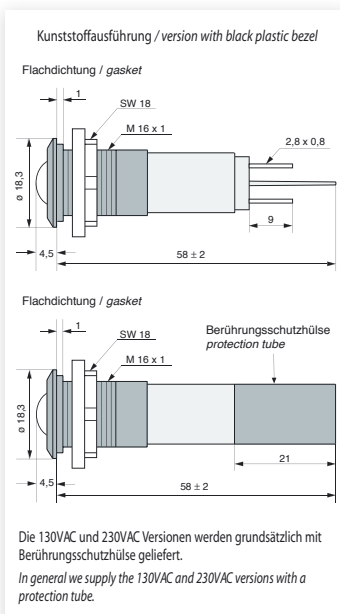

Part Number	Colour	Voltage	Typ. Current	Typ. Lumi. Intensity
Schwarzer Kunststoffreflektor / Black plastic bezel				
19401130	red	130V AC	6mA AC	600mcd
19401135	green	130V AC	6mA AC	510mcd
19401132	yellow	130V AC	6mA AC	400mcd
19401137	blue	130V AC	6mA AC	150mcd
1940113W	white	130V AC	3mA AC	450mcd
19401230	red	230V AC	3mA AC	300mcd
19401235	green	230V AC	3mA AC	255mcd
19401232	yellow	230V AC	3mA AC	200mcd
19401237	blue	230V AC	3mA AC	75mcd
1940123W	white	230V AC	1,5mA AC	225mcd
Hochglanzverchromter Metallreflektor / Satin chrome bezel				
19400130M	red	130V AC	6mA AC	600mcd
19400135M	green	130V AC	6mA AC	510mcd
19400132M	yellow	130V AC	6mA AC	400mcd
19400137M	blue	130V AC	6mA AC	150mcd
1940013WM	white	130V AC	3mA AC	450mcd
19400230M	red	230V AC	3mA AC	300mcd
19400235M	green	230V AC	3mA AC	255mcd
19400232M	yellow	230V AC	3mA AC	200mcd
19400237M	blue	230V AC	3mA AC	75mcd
1940023WM	white	230V AC	1,5mA AC	225mcd
Schwarzverchromter Metallreflektor / Black chrome bezel				
19401130M	red	130V AC	6mA AC	600mcd
19401135M	green	130V AC	6mA AC	510mcd
19401132M	yellow	130V AC	6mA AC	400mcd
19401137M	blue	130V AC	6mA AC	150mcd
1940113WM	white	130V AC	3mA AC	450mcd
19401230M	red	230V AC	3mA AC	300mcd
19401235M	green	230V AC	3mA AC	255mcd
19401232M	yellow	230V AC	3mA AC	200mcd
19401237M	blue	230V AC	3mA AC	75mcd
1940123WM	white	230V AC	1,5mA AC	225mcd
Mattverchromter Metallreflektor / Matt chrome bezel				
19402130M	red	130V AC	6mA AC	600mcd
19402135M	green	130V AC	6mA AC	510mcd
19402132M	yellow	130V AC	6mA AC	400mcd
19402137M	blue	130V AC	6mA AC	150mcd
1940213WM	white	130V AC	3mA AC	450mcd
19402230M	red	230V AC	3mA AC	300mcd
19402235M	green	230V AC	3mA AC	255mcd
19402232M	yellow	230V AC	3mA AC	200mcd
19402237M	blue	230V AC	3mA AC	75mcd
1940223WM	white	230V AC	1,5mA AC	225mcd

Maximale Frontplattenstärke 11mm / Maximum panel thickness 11mm
Andere Spannungen auf Anfrage / Other voltages on request

EINBAUDURCHMESSER
MOUNTING HOLE

6 mm

8 mm

12 mm

14 mm

16 mm

19 mm

22 mm

ZUBEHÖR
ACCESSORIES