

LED Signalleuchten LED Panel Mount Indicators

LED Signalleuchten für den Einbaudurchmesser von 22mm (+0,5mm) sind mit verschiedenfarbigen, diffusen 16mm Linsen bestückt.

Zur Auswahl stehen zwei Linsenformen:

- runde Linse
- flache Linse

Sie sind mit hochglanzverchromten, schwarzverchromten oder mattverchromten Messingreflektoren sowie schwarzen Kunststoffreflektoren lieferbar. Der Anschluss erfolgt in der Regel über Flachstecker 2,8 x 0,8mm. Die entsprechenden Flachsteckhülsen finden Sie auf der Zubehör-Seite. Die Montage der LED Signalleuchten erfolgt mittels der mitgelieferten Sprengringe und Muttern.

Messingflachstecker = Anode (+)

verzinnter Flachstecker = Kathode (-)

LED panel mount indicators for a 22mm (+0.5mm) mounting hole are manufactured with coloured diffused 16mm lenses.

These indicators can be delivered with two different lens shapes:



- round lens
- flat lens

These lenses are fitted in high quality satin chrome, black chrome or matt chrome metal bezels or in black plastic bezels, supplied with fixing nut and washer. Connection is usually by faston tab terminals 2.8 x 0.8mm. Suitable crimp connectors can be found on the page for accessories.

Brass terminals = anode (+)

Tinned terminals = cathode (-)

Standardreflektor runde Linse mit Vorwiderstand und Brückengleichrichter IP67 / Standard bezel round lens with resistor and bridge rectifier IP67

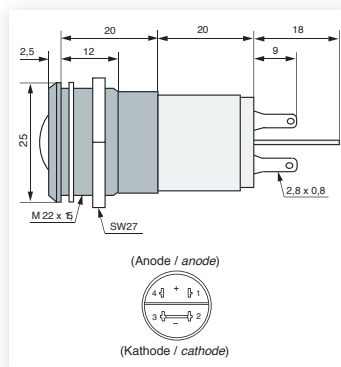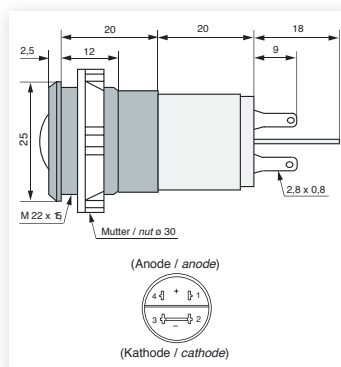

Part Number	Colour	Voltage	Typ. Current	Typ. Lumi. Intensity
Schwarzer Kunststoffreflektor / Black plastic bezel				
195A1250UC	red	12V AC/DC	16mA AC/DC	160mcd
195A1251UC	green	12V AC/DC	16mA AC/DC	400mcd
195A1252UC	yellow	12V AC/DC	16mA AC/DC	350mcd
195A1257UC	blue	12V AC/DC	16mA AC/DC	280mcd
195A125WUC	white	12V AC/DC	7mA AC/DC	1050mcd
195A1350UC	red	24V AC/DC	16mA AC/DC	160mcd
195A1351UC	green	24V AC/DC	16mA AC/DC	400mcd
195A1352UC	yellow	24V AC/DC	16mA AC/DC	350mcd
195A1357UC	blue	24V AC/DC	16mA AC/DC	280mcd
195A135WUC	white	24V AC/DC	8mA AC/DC	1200mcd
Hochglanzverchromter Metallreflektor / Satin chrome bezel				
195A0250MUC	red	12V AC/DC	16mA AC/DC	160mcd
195A0251MUC	green	12V AC/DC	16mA AC/DC	400mcd
195A0252MUC	yellow	12V AC/DC	16mA AC/DC	350mcd
195A0257MUC	blue	12V AC/DC	16mA AC/DC	280mcd
195A025WMUC	white	12V AC/DC	7mA AC/DC	1050mcd
195A0350MUC	red	24V AC/DC	16mA AC/DC	160mcd
195A0351MUC	green	24V AC/DC	16mA AC/DC	400mcd
195A0352MUC	yellow	24V AC/DC	16mA AC/DC	350mcd
195A0357MUC	blue	24V AC/DC	16mA AC/DC	280mcd
195A035WMUC	white	24V AC/DC	8mA AC/DC	1200mcd
Schwarzverchromter Metallreflektor / Black chrome bezel				
195A1250MUC	red	12V AC/DC	16mA AC/DC	160mcd
195A1251MUC	green	12V AC/DC	16mA AC/DC	400mcd
195A1252MUC	yellow	12V AC/DC	16mA AC/DC	350mcd
195A1257MUC	blue	12V AC/DC	16mA AC/DC	280mcd
195A125WMUC	white	12V AC/DC	7mA AC/DC	1050mcd
195A1350MUC	red	24V AC/DC	16mA AC/DC	160mcd
195A1351MUC	green	24V AC/DC	16mA AC/DC	400mcd
195A1352MUC	yellow	24V AC/DC	16mA AC/DC	350mcd
195A1357MUC	blue	24V AC/DC	16mA AC/DC	280mcd
195A135WMUC	white	24V AC/DC	8mA AC/DC	1200mcd
Mattverchromter Metallreflektor / Matt chrome bezel				
195A2250MUC	red	12V AC/DC	16mA AC/DC	160mcd
195A2251MUC	green	12V AC/DC	16mA AC/DC	400mcd
195A2252MUC	yellow	12V AC/DC	16mA AC/DC	350mcd
195A2257MUC	blue	12V AC/DC	16mA AC/DC	280mcd
195A225WMUC	white	12V AC/DC	7mA AC/DC	1050mcd
195A2350MUC	red	24V AC/DC	16mA AC/DC	160mcd
195A2351MUC	green	24V AC/DC	16mA AC/DC	400mcd
195A2352MUC	yellow	24V AC/DC	16mA AC/DC	350mcd
195A2357MUC	blue	24V AC/DC	16mA AC/DC	280mcd
195A235WMUC	white	24V AC/DC	8mA AC/DC	1200mcd

Maximale Frontplattenstärke 8,5mm / Maximum panel thickness 8.5mm

Andere Spannungen auf Anfrage / Other voltages on request