

Home - Fischerelektronik - LA 14

 fischerelektronik.de/web_fischer/en_GB/VA/LA1440024/datasheet.xhtml





Data sheet Product LA 14 ...

- [Print data sheet](#)
- [Recommend page](#)

Features

width:	120 mm
height:	120 mm
length:	100 mm / 150 mm / 200 mm / 250 mm / 300 mm / 400 mm
thermal resistance:	0.175 - 0.07 K/W
surface:	raw degreased aluminium (by the metre raw aluminium)
operating voltage of the fan motor:	• 24 V DC • 230 V AC

Technical Drawing

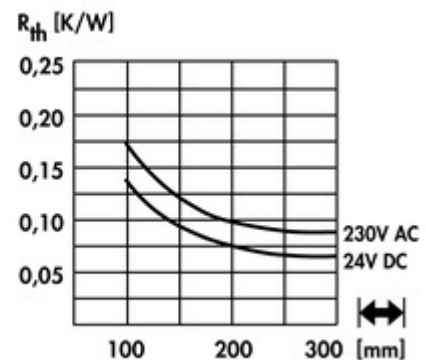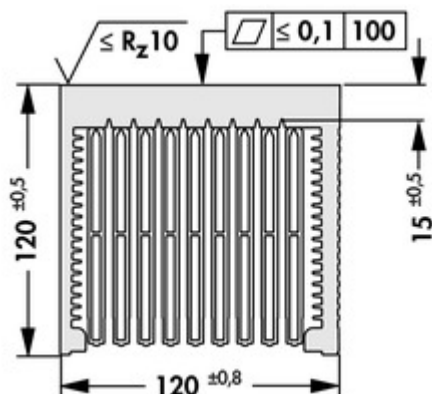

Fan

type:	ebmpapst 4184NXH
-------	------------------

dimensions:	119x119x38 mm
-------------	---------------

tension:	24 V DC
----------	---------

power inout:	11 W
--------------	------

max. air volume:	237 m ³ /h
------------------	-----------------------

temperature range:	-30°C ... +70°C
--------------------	-----------------

speed:	4,400 min ⁻¹
--------	-------------------------

noise level:	57 dB(A)
--------------	----------

weight:	390 g
---------	-------

failure rate (L ₁₀):	L ₁₀ > 70,000 h (40°C)
----------------------------------	-----------------------------------

type:	ebmpapst 4656N
-------	----------------

dimensions:	119x119x38 mm
-------------	---------------

tension:	230 V AC
----------	----------

power inout:	19 W
--------------	------

max. air volume:	160 m ³ /h
------------------	-----------------------

temperature range:	-40°C... +85°C
--------------------	----------------

speed:	2,650 min ⁻¹
--------	-------------------------

noise level:	47 dB(A)
--------------	----------

weight: 550 g

failure rate (L_{10}): $L_{10} > 37,500 \text{ h (40°C)}$

Fischer Elektronik GmbH & Co. KG
DEUTSCHLAND • GERMANY • ALLEMAGNE

Nottebohmstraße 28
58511 Lüdenscheid

Telefon +49 2351 435-0
Telefax +49 2351 45754

info@fischerelektronik.de
www.fischerelektronik.de