

Home - Fischerelektronik - LA 15



fischerelektronik.de/web_fischer/en_GB/VA/LA1515024/datasheet.xhtml



Features

width:	240 mm
height:	120 mm
length:	150 mm
thermal resistance:	0.083 - 0.032 K/W
surface:	raw degreased aluminium (by the metre raw aluminium)
operating voltage of the fan motor:	• 24 V DC • 230 V AC

Technical Drawing

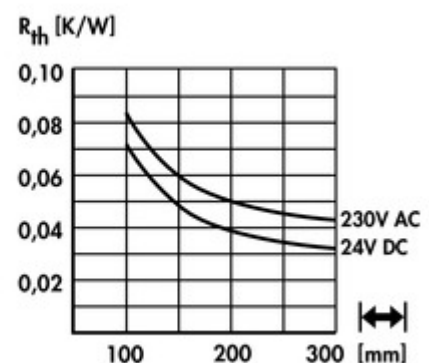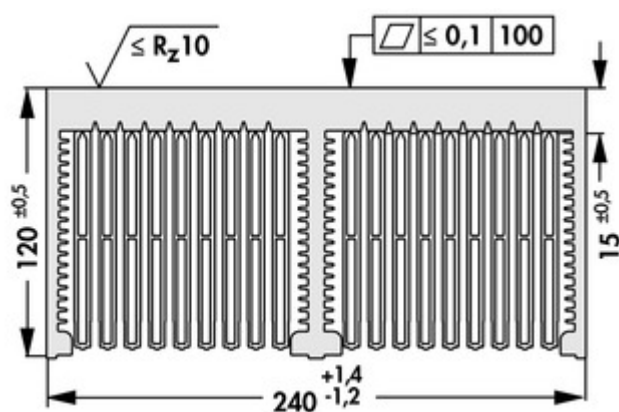

Fan

type: ebmpapst 4184NXH

dimensions:	119x119x38 mm
tension:	24 V DC
power inout:	11 W
max. air volume:	237 m ³ /h
temperature range:	-30°C ... +70°C
speed:	4,400 min ⁻¹
noise level:	57 dB(A)
weight:	390 g
failure rate (L ₁₀):	L ₁₀ > 70,000 h (40°C)
type:	ebmpapst 4656N
dimensions:	119x119x38 mm
tension:	230 V AC
power inout:	19 W
max. air volume:	160 m ³ /h
temperature range:	-40°C... +85°C
speed:	2,650 min ⁻¹
noise level:	47 dB(A)
weight:	550 g
failure rate (L ₁₀):	L ₁₀ > 37,500 h (40°C)

